

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0399600110

Status:

Active

Overview:

Eurostyle Terminal Blocks

Description:

8.00mm Beau Eurostyle Fixed Mount PCB Terminal Block, High Voltage 10 Circuits

Documents:


3D Model

3D Model (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Terminal Blocks
Series	39960
Application	N/A
Component Type	One Piece
Overview	Eurostyle Terminal Blocks
Product Name	Eurostyle Fixed Mount
Type	Euro Block
UPC	756054590287
Physical	
Circuits (Loaded)	10
Circuits (maximum)	10
Color - Resin	Black
Entry Angle	Horizontal
Lock to Mating Part	None
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Number of Rows	1
Orientation	Vertical
PC Tail Length	4.06mm
PCB Retention	None
Panel Mount	No
Pitch - Mating Interface	8.00mm
Pitch - Termination Interface	8.00mm
Plating min - Mating	3.810µm
Plating min - Termination	3.810µm
Polarized to Mating Part	N/A
Shrouded	Fully
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	130°C
Wire Size AWG	10, 12, 14, 16, 18, 20, 22
Wire Size mm²	0.50-4.00
Electrical	
Current - Maximum per Contact	30.0A
Voltage - Maximum	600V
Solder Process Data	
Lead-freeProcess Capability	WAVE
Material Info	
Engineering Number	960510
Reference - Drawing Numbers	
Sales Drawing	SD-39960-002

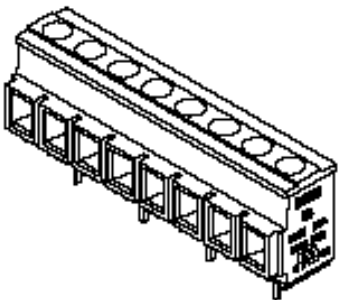

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - ED/71/2019 (16 July 2019)	
lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

39960 Series

This document was generated on 07/30/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39960-0110