

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0399600710

Status:

Active

Overview:

Eurostyle Terminal Blocks

Description:

8.00mm Beau Eurostyle Fixed Mount PCB Terminal Block, 600 Voltage, 30A, 10 Circuits

Documents:

- 3D Model

Drawing (PDF)
- 3D Model (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Terminal Blocks

Series

39960

Application

N/A

Component Type

One Piece

Overview

Eurostyle Terminal Blocks

Product Name

Eurostyle Fixed Mount

Type

Euro Block

UPC

800756901152

Physical

Circuits (Loaded)

10

Circuits (maximum)

10

Color - Resin

Black

Entry Angle

Vertical

Lock to Mating Part

None

Material - Metal

High Performance Alloy (HPA)

Material - Plating Mating

Tin

Material - Plating Termination

Tin

Material - Resin

Polyester

Number of Rows

1

Orientation

Vertical

PC Tail Length

4.10mm

PCB Thickness - Recommended

3.18mm

Panel Mount

No

Pitch - Mating Interface

8.00mm

Pitch - Termination Interface

8.00mm

Plating min - Mating

3.810µm

Plating min - Termination

3.810µm

Polarized to Mating Part

Yes

Shrouded

Fully

Stackable

No

Surface Mount Compatible (SMC)

No

Temperature Range - Operating

-40° to +140°C

Wire Size AWG

10, 12, 14, 16, 18, 20, 22

Wire Size mm²

2.50-25.00

Electrical

Current - Maximum per Contact

30.0A

Voltage - Maximum


600V

Material Info

Reference - Drawing Numbers

Sales Drawing

SD-39960-003

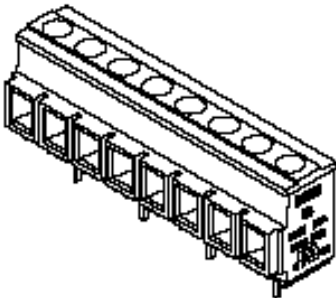

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

39960 Series

Mates With

N/A

This document was generated on 07/28/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39960-0710