

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0399900309
Status: Active
Overview: Eurostyle™ Terminal Blocks
Description: 5.00mm Pitch Beau™ Eurostyle™ Screw Clamp Plug, 9 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
UL E48521


General
Product Family Terminal Blocks
Series 39990
Application N/A
Comments Gold plating available
Component Type Plug
Overview Eurostyle™ Terminal Blocks
Product Name Eurostyle™ Pluggable
Type Euro Block
UPC 800756375373

Physical
Circuits (Loaded) 9
Color - Resin Black
Entry Angle Horizontal
Flammability 94V-0
Lock to Mating Part Yes
Material - Metal Brass
Material - Resin Nylon
Number of Rows 1
Orientation Vertical
PCB Retention N/A
Panel Mount No
Pitch - Mating Interface 5.00mm
Pitch - Termination Interface 5.00mm
Polarized to Mating Part Yes
Shrouded Fully
Stackable No
Surface Mount Compatible (SMC) No
Temperature Range - Operating 110°C
Termination Interface: Style Surface Mount
Wire Size AWG 12, 14, 16, 18, 20, 22, 24

Electrical
Current - Maximum per Contact 10.0A
Voltage - Maximum 300V

Material Info
Engineering Number 990909

Reference - Drawing Numbers
Sales Drawing SD-39990-001, SD-39990-003

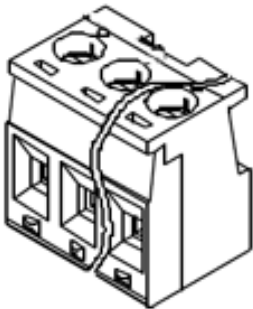

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant with Exemption 6(c) REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS Not Relevant ELV Not Relevant RoHS Phthalates Not Reviewed
--	--

Search Parts in this Series
[39990 Series](#)

Mates With
[39990-0409](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

39990-0309