

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0423751923](#)
Status: **Active**
Description: KK 100 Hdr Assy Bkwy 03 Ckt 30 SGold

Documents:

Drawing (PDF)	Packaging Specification PK-40873-0041-001 (PDF)
Product Specification PS-10-07-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

Application tooling part link

Application Tooling Part Link	11-20-1230
-------------------------------	------------

General

Product Family	PCB Headers
Series	42375
Product Name	KK 254
UPC	800753813373

Physical

Flammability	94V-0
Net Weight	0.189/g

Electrical

Voltage - Maximum	500V
-------------------	------


Solder Process Data

Duration at Max. Process Temperature (seconds)	005
Lead-freeProcess Capability	WAVE
Max. Cycles at Max. Process Temperature	001
Process Temperature max. C	235

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-40873-0041-001
Product Specification	PS-10-07-001
Sales Drawing	SD-42375-001-001

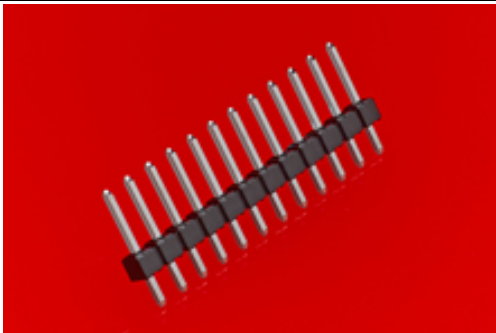

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

42375 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[42375-1923](#)