

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0424104168

Status:

Active

Overview:

Magnetic and Modular Jacks/Plugs

Description:

Modular Jack, Vertical, 4/4, Panel Stops

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Product Specification PS-42410-001 (PDF)

Packaging Specification PK-42410-492-001 (PDF)

Test Summary TS-42878-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR19980

UL

E107635

General

Product Family

Modular Jacks/Plugs

Series

42410

Component Type

PCB Jack

Magnetic

No

Overview

Magnetic and Modular Jacks/Plugs

Performance Category

3

Power over Ethernet (PoE)

N/A

Product Name

Modular Jack 4/4

UPC

800753683563

Physical

Boot Color

N/A

Color - Resin

Black

Durability (mating cycles max)

500

Flammability

94V-0

Inverted / Top Latch

N/A

Jack Height

16.38mm

Keying to Mating Part

None

Lightpipes/LEDs

None

Material - Metal

Phosphor Bronze

Material - Plating Mating

Gold

Material - Plating Termination

Tin

Material - Resin

Polyester

Net Weight

2.104/g

Orientation

Vertical (Top Entry)

PCB Locator

Yes

PCB Retention

Yes

PCB Thickness - Recommended

1.57mm

Packaging Type

Tray

Panel Mount

With Flange

Pitch - Mating Interface

1.02mm

Pitch - Termination Interface

1.27mm

Plating min - Mating

1.270µm

Plating min - Termination

2.540µm

Port Configuration

1x1

Positions / Loaded Contacts

4/4

Surface Mount Compatible (SMC)

No

Temperature Range - Operating

-40° to +85°C

Termination Interface: Style


Through Hole

Waterproof / Dustproof

No

Wire/Cable Type

N/A

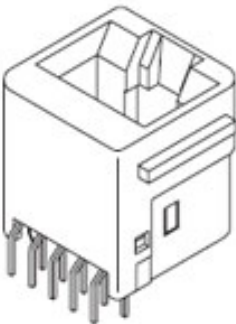

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series  
42410 Series

**Electrical**

|                               |               |
|-------------------------------|---------------|
| Current - Maximum per Contact | 1.5A          |
| Grounding to PCB              | No            |
| Grounding to Panel            | None          |
| Shielded                      | No            |
| Voltage - Maximum             | 150V AC (RMS) |

**Solder Process Data**

|                                                |      |
|------------------------------------------------|------|
| Duration at Max. Process Temperature (seconds) | 005  |
| Lead-freeProcess Capability                    | WAVE |
| Max. Cycles at Max. Process Temperature        | 001  |
| Process Temperature max. C                     | 235  |

**Material Info**

**Reference - Drawing Numbers**

|                         |                    |
|-------------------------|--------------------|
| Packaging Specification | PK-42410-492-001   |
| Product Specification   | PS-42410-001       |
| Sales Drawing           | SDA-42410-XXXX-001 |
| Test Summary            | TS-42878-001-001   |

This document was generated on 09/13/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[42410-4168](#)