

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0430610007

Status:

Active

Overview:

SPOX Connector System

Description:

3.96mm Pitch SPOX Housing, 7 Circuits, Natural

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR19980

UL

E29179

General

Product Family

Crimp Housings

Series

43061

Application

Power, Wire-to-Board

Comments

Glow Wire Equivalent Part Number 430613007

Overview

SPOX Connector System

Product Name

SPOX

UPC

800753576407

Physical

Breakaway

No

Circuits (maximum)

7

Circuits Detail

7

Color - Resin

Natural

Flammability

94V-0

Gender

Receptacle

Glow-Wire Capable

No

Keying to Mating Part

None

Lock to Mating Part

Yes

Material - Resin

Polyester

Net Weight

2.313/g

Number of Rows

1

Packaging Type

Bag

Panel Mount

No

Pitch - Mating Interface

3.96mm

Pitch - Termination Interface

3.96mm

Polarized to Mating Part

Yes

Stackable

No

Temperature Range - Operating

0° to +75°C

Solder Process Data

Lead-freeProcess Capability


N/A

Material Info

Reference - Drawing Numbers

Sales Drawing

SD-43061-001, SD-43061-002

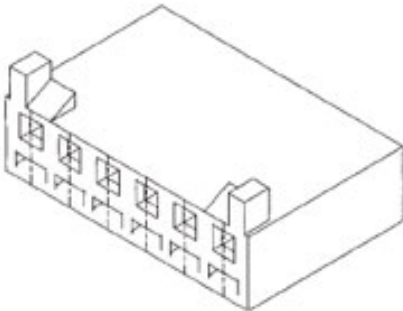

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

43061 Series

Mates With

3.96mm Pitch KK or SPOX headers

Use With

SPOX Terminal 5194 , 5225

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[43061-0007](#)