

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0433352003

Status:

Active

Description:

7.50mm Pitch, Flat Blade Appliance Receptacle Housing, Single Row, 3 Circuits, Nylon PA66, UL 94V-0, Black with TPA

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PSX-43335-9999-001 (PDF)

Packaging Specification PK-43335-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

UL

LR19980

E29179

General

Product Family

Series

Application

Comments

Crimp Housings

43335

Power, Wire-to-Wire

This Molex product is manufactured from material that has the following ratings, tested by independent agencies :. a) A Glow Wire Ignition Temperature (GWIT) of at least 775 deg C per IEC 60695-2-13.. b) A Glow Wire Flammability Index (GWFI) above 850 deg C per IEC 60695-2-12.and hence complies with the requirements set out in the International Standard IEC 60335-1 5th edition - household and similar electrical appliances - safety; section 30 Resistance to heat and fire.<P><P>The customers using this product must determine its suitability for use in their particular application through testing or other acceptable means as described in end-product glow-wire flammability test standard IEC 60695-2-11 and any applicable product end-use standard(s).<P>If it is determined during the customer's evaluation of suitability, that higher performance is required, please contact Molex for possible product options.

Flat Blade

822348665631

Product Name

UPC

Physical

Breakaway

Circuits (maximum)

Color - Resin

Flammability

Gender

Glow-Wire Capable

Keying to Mating Part

Lock to Mating Part

Material - Resin

Net Weight

Number of Rows

Packaging Type

Panel Mount

Pitch - Mating Interface

Pitch - Termination Interface

Polarized to Mating Part

Ports

No

3

Black

94V-0

Receptacle

No

None

Yes

Nylon

2.343/g

1

Bag


No

7.50mm

7.50mm

Yes

1

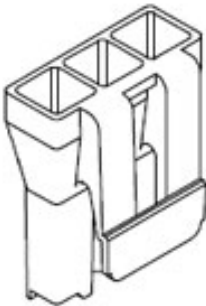

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per -

D(2021)4569-DC (8

July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

43335 Series

Mates With

43180 Flat Blade Plug Housing

Use With

43375 Female Terminals

Stackable	No
Temperature Range - Operating	-40° to +75°C
<b>Solder Process Data</b>	
Lead-freeProcess Capability	N/A
<b>Material Info</b>	
Engineering Number	43352003
<b>Reference - Drawing Numbers</b>	
Packaging Specification	PK-43335-001-001
Product Specification	PSX-43335-9999-001
Sales Drawing	SD-43335-X003-001

This document was generated on 08/26/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[43335-2003](#)