

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0436450300**  
**Status:** **Active**  
**Overview:** Micro-Fit Connector System  
**Description:** Micro-Fit 3.0 Receptacle Housing, Single Row, 3 Circuits, UL 94V-0, Low-Halogen, Black

**Documents:**

<a href="#">3D Model (PDF)</a>	<a href="#">Packaging Specification PK-43645-001-001 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Test Summary 430450005-TS-000 (PDF)</a>
<a href="#">3D Model</a>	<a href="#">Test Summary TS-43045-001-001 (PDF)</a>
<a href="#">Product Specification 436500001-PS-JA-000 (PDF)</a>	<a href="#">Test Summary TS-43045-002-001 (PDF)</a>
<a href="#">Product Specification 436500001-PS-KO-000 (PDF)</a>	<a href="#">Test Summary TS-43045-003-001 (PDF)</a>
<a href="#">Product Specification 436500001-PS-SP-000 (PDF)</a>	<a href="#">Test Summary TS-46235-001-001 (PDF)</a>
<a href="#">Product Specification PS-43650-001 (PDF)</a>	<a href="#">Datasheet (PDF)</a>
<a href="#">Application Specification 430250000-AS-000 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**Agency Certification**

CSA	LR19980
UL	E29179

**General**

Product Family	Crimp Housings
Series	<a href="#">43645</a>
Application	Power, Wire-to-Board, Wire-to-Wire
Overview	<a href="#">Micro-Fit Connector System</a>
Product Name	Micro-Fit 3.0
UPC	800754366175

**Physical**

Circuits (maximum)	3
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	0.456/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C


**Solder Process Data**

Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

**Reference - Drawing Numbers**

Application Specification	430250000-AS-000
Packaging Specification	PK-43645-001-001
Product Specification	436500001-PS-JA-000, 436500001-PS-KO-000, 436500001-PS-SP-000, PS-43650-001
Sales Drawing	436450000-SD-000

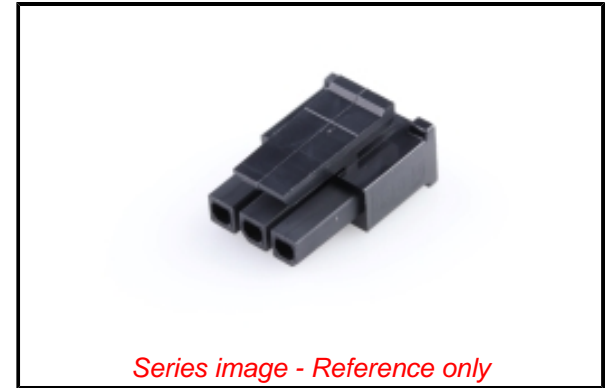

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Compliant

Not Contained

**Search Parts in this Series**

[43645 Series](#)

**Mates With**

Micro-Fit 3.0 Plug Housings [43640](#)  
<br>Micro-Fit TPA Plug Housing [200875](#)  
<br>Micro-Fit 3.0 Headers [43650](#) <br>  
Micro-Fit 3.0 Cable Assembly [214752](#) ,  
[214753](#)

**Use With**

Micro-Fit 3.0 Female Crimp Terminals  
[43030](#) <br> Micro-Fit RMF Female Crimp  
Terminals [46235](#) <br>Micro-Fit 3.0 Pre-  
Crimped Leads [797580002](#) , [797580004](#) ,  
[797580010](#) , [797580012](#) , [214760](#) , [214761](#)

430450005-TS-000, TS-43045-001-001,  
TS-43045-002-001, TS-43045-003-001,  
TS-46235-001-001

This document was generated on 11/12/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[43645-0300](#)