


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0441670001
Status: Active
Description: Flat Blade Appliance Dryer Motor Crimp Housing, 6 Circuit, with Tool Removable Latch

Documents:	
3D Model	Product Specification PS-43374-001-001 (PDF)
3D Model (PDF)	Packaging Specification PK-42865-001-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	42865
Application	Power
Product Name	Flat Blade
UPC	800753943735
Physical	
Circuits (maximum)	6
Color - Resin	Natural
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	7.708/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	5.59mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +75°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-42865-001-001
Product Specification	PS-43374-001-001
Sales Drawing	SD-44167-001-001

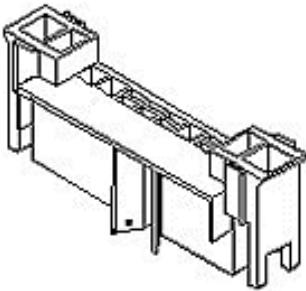

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free Status Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
42865 Series

Use With
Crimp Terminals 1508 , 43374 , 41422

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[44167-0001](#)