


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0451330403](#)
Status: **Active**
Overview: [Ultra-Fit Power Connectors](#)
Description: Ultra-Fit-to-Ultra-Fit Off-the-Shelf (OTS) Cable Assembly, Dual Row, 300.00mm Length, 4 Circuits, Black

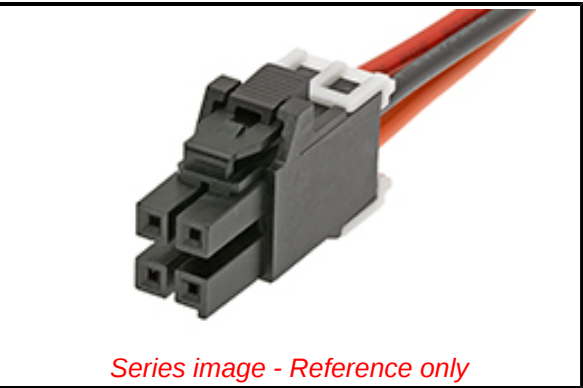

Documents:
[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family Cable Assemblies
Series [45133](#)
Application Power, Wire-to-Board
Assembly Configuration Dual Ended Connectors
Connector to Connector Ultra-Fit-to-Ultra-Fit
Overmolded No
Overview [Ultra-Fit Power Connectors](#)
Product Name Ultra-Fit
Type Discrete Wire Assembly
UPC 889056738682

Physical
Cable Length 300.00mm
Circuits (Loaded) 4
Color - Resin Black
Gender Female-Female
Lock to Mating Part Yes
Material - Metal High Conductivity Copper
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Nylon
Net Weight 21.900/g
Number of Rows 2
Packaging Type Bag
Pitch - Mating Interface 3.50mm
Plating min - Mating 1.524µm
Plating min - Termination 1.524µm
Single Ended No
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 2.35mm
Wire Size AWG 16
Wire/Cable Type UL 1061

Electrical
Current - Maximum per Contact 12.0A
Voltage - Maximum 300V

Material Info

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[45133](#) Series

Mates With

Ultra-Fit Right Angle Header [172316](#)

Ultra-Fit Vertical Header [172298](#) ,
[172299](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[45133-0403](#)