


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0467109000

Status: Active

Overview: EXTreme Ten60Power High-Current Connector

Description: EXTreme Ten60Power Wire-to-Board Harness Kit, 4 Power Circuits, 15 Signal Circuits, Black

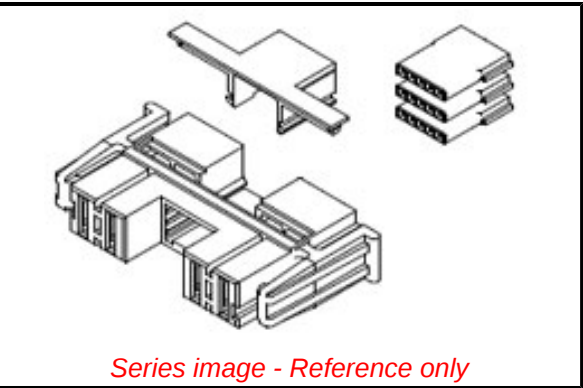

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Crimp Housings
Series	46710
Application	Power, Signal, Wire-to-Board
Comments	Includes main housing, TPA and 3 signal housing
Overview	EXTreme Ten60Power High-Current Connector
Product Name	EXTreme Ten60Power
UPC	883906882945
Physical	
Circuits (maximum)	20
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	11.532/g
Number of Rows	1, 3
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm, 7.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers

Sales Drawing SD-46710-900

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per -
ED/30/2017 (7 July
2017)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

46710 Series

Mates With

464371023 EXTreme Ten60Power Right
Angle Plug

Use With

44262 Crimp Terminal Blade, 70058 SL
Female Crimp Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[46710-9000](#)