

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0497026802](#)
Status: **Active**
Description: 2.28mm Tab-Type Female Crimp Terminal, Low Insertion Force Type, Middle Size, Tin Plated, AVSS (CAVS) 0.5, 0.85, 1.25mm²;


Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-49006-001-001 \(PDF\)](#)
[Packaging Specification PK-49702-001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Crimp Terminals
Series	49702
Application	Power, Wire-to-Wire
Crimp Quality Equipment	Yes
Product Name	N/A
UPC	822348108299
Physical	
Gender	Female
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.391/g
Packaging Type	Reel
Plating min - Mating	0.813µm
Plating min - Termination	0.813µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	2.10-1.60mm
Wire Size AWG	16, 18, 20
Wire Size mm ²	1.25-0.50

Material Info

Reference - Drawing Numbers

Crimp Specification	CS-49702-001-001
Packaging Specification	PK-49702-001-001
Product Specification	PS-49006-001-001
Sales Drawing	SD-49702-001

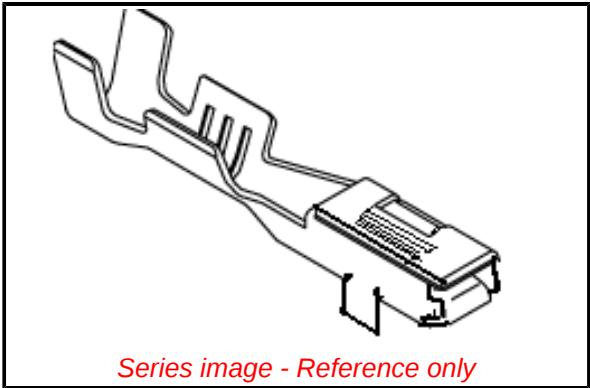

Series image - Reference only

EU ELV Compliant	
EU RoHS Compliant REACH SVHC Not Contained Per - ECHA_01_2020 (16 January 2020 Halogen-Free Status Not Reviewed For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Not Relevant Compliant Not Contained

Search Parts in this Series
[49702 Series](#)

Mates With
[579196702](#)

Use With
[490094610](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

49702-6802