


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0500588300](#)
Status: **Active**
Description: 1.25mm Pitch Wire-to-Board Receptacle Terminal for 26-30 AWG, Phosphor Bronze, Pre-Tin Plating

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Crimp Terminals
Series	50058
Application	Signal
Crimp Quality Equipment	Yes
Current Derating Order No	987651-3691
Product Name	N/A
UPC	822348702398
Physical	
Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.014/g
Packaging Type	Reel
Plating min - Mating	0.813µm
Plating min - Termination	0.813µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.00mm max.
Wire Size AWG	26, 28, 30
Wire Size mm²	N/A
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-50058-001

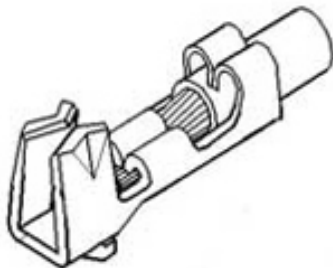

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per -ED/01/2017 (12 January 2017) Halogen-Free Status Low-Halogen Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[50058](#) Series

Mates With
[50125](#) Crimp Terminal 26-28 AWG, [50133](#)
Crimp Terminal 28-32 AWG

Use With
[51021](#) Housing

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

50058-8300