

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0506370128

Status:

Active

Description:

2.00mm Pitch Crimp Terminal, Female, Bag, Lead Free

Documents:

3D Model

Product Specification PS-58719-006-001 (PDF)

Drawing (PDF)


RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	50637
Application	Power, Wire-to-Wire
Crimp Quality Equipment	Yes
Packaging Alternative	506370028 (Reel)
Product Name	N/A
UPC	822348143436
Physical	
Gender	Female
Material - Metal	Copper
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Net Weight	608.741/mg
Packaging Type	Bag
Plating min - Mating	0.102µm
Plating min - Termination	1.016µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.20-3.80mm
Wire Size AWG	14, 16, 18
Wire Size mm²	N/A

Material Info

Reference - Drawing Numbers

Product Specification	PS-58719-006-001
Sales Drawing	SD-50637-001

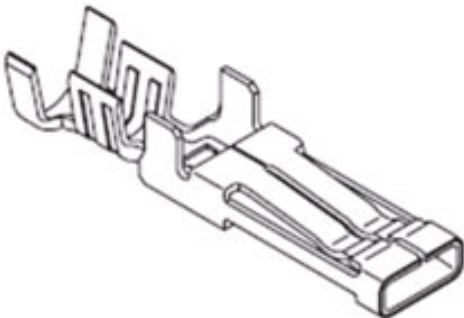

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/71/2019 (16 July 2019)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

50637 Series

Mates With

50638 Male Crimp Terminal

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Extraction Tool for RCM Connector System	638133501
Hand Crimp Tool for 2.00mm Pitch Female Crimp Terminals	638231400

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[50637-0128](#)