

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0511910900

Status:


Active

Overview:

Mini-Latch Wire-to-Board / Wire-to-Wire Connector System

Description:

2.50mm Pitch Mini-Latch Wire-to-Wire and Wire-to-Board Receptacle Housing, with Guide Rails, 9 Circuits

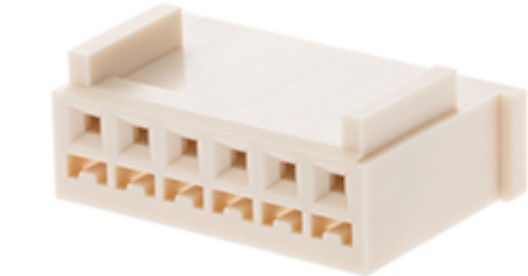

Series image - Reference only

|                                                               |                                                                  |
|---------------------------------------------------------------|------------------------------------------------------------------|
| Documents:                                                    |                                                                  |
| <a href="#">3D Model</a>                                      | <a href="#">Product Specification PS-51191-003-001 (PDF)</a>     |
| <a href="#">3D Model (PDF)</a>                                | <a href="#">Application Specification 511910000-AS-000 (PDF)</a> |
| <a href="#">Drawing (PDF)</a>                                 | <a href="#">Packaging Specification 511919200-SPK-200 (PDF)</a>  |
| <a href="#">Product Specification 2055050000-PS-000 (PDF)</a> | <a href="#">RoHS Certificate of Compliance (PDF)</a>             |
| <a href="#">Product Specification 511910000-PS-000 (PDF)</a>  |                                                                  |

|                               |                                                          |
|-------------------------------|----------------------------------------------------------|
| Agency Certification          |                                                          |
| UL                            | E29179                                                   |
| General                       |                                                          |
| Product Family                | Crimp Housings                                           |
| Series                        | 51191                                                    |
| Application                   | Signal, Wire-to-Board, Wire-to-Wire                      |
| Overview                      | Mini-Latch Wire-to-Board / Wire-to-Wire Connector System |
| Product Name                  | Mini-Latch                                               |
| UPC                           | 800753327849                                             |
| Physical                      |                                                          |
| Circuits (maximum)            | 9                                                        |
| Flammability                  | 94V-0                                                    |
| Gender                        | Receptacle                                               |
| Glow-Wire Capable             | No                                                       |
| Material - Resin              | Nylon                                                    |
| Net Weight                    | 875.900/mg                                               |
| Number of Rows                | 1                                                        |
| Packaging Type                | Bag                                                      |
| Panel Mount                   | No                                                       |
| Pitch - Mating Interface      | 2.50mm                                                   |
| Stackable                     | No                                                       |
| Temperature Range - Operating | -40° to +105°C                                           |
| Material Info                 |                                                          |
| Reference - Drawing Numbers   |                                                          |
| Application Specification     | 511910000-AS-000                                         |
| Packaging Specification       | 511919200-SPK-200                                        |
| Product Specification         | 2055050000-PS-000, 511910000-PS-000, PS-51191-003-001    |
| Sales Drawing                 | SD-51191-004-001                                         |

|                                                               |               |
|---------------------------------------------------------------|---------------|
| EU ELV                                                        |               |
| Not Relevant                                                  |               |
| EU RoHS                                                       | China RoHS    |
| Compliant                                                     |               |
| REACH SVHC                                                    |               |
| Not Contained Per - D(2021)4569-DC (8 July 2021)              |               |
| Halogen-Free                                                  |               |
| Status                                                        |               |
| Low-Halogen                                                   |               |
| For more information, please visit <a href="#">Contact US</a> |               |
| China ROHS                                                    | Green Image   |
| ELV                                                           | Not Relevant  |
| RoHS Phthalates                                               | Not Contained |

Search Parts in this Series

51191 Series

Mates With

5045 Vertical Header . 5046 Right Angle Header . 5240 Plug Housing

Use With

50802 Crimp Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

51191-0900