

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0512010001](#)
Status: **Active**
Overview: [HMC Heavy Duty Rectangular Connectors](#)
Description: HMC Rectangular Industrial Dust Cover for Panel-Mount Bracket, Multi-Module Type, 36 Circuits

Documents:
[3D Model](#) [Application Specification AS-58696-004-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Application Specification AS-58696-005-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [Application Specification AS-58696-006-001 \(PDF\)](#)
[Product Specification PS-58691-004-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family I/O Connectors
Series [51201](#)
Application Panel-Mount
Component Type Dust Cover for Panel-Mount Bra
Overview [HMC Heavy Duty Rectangular Connectors](#)
Product Name HMC
Type N/A
UPC 800753247277

Physical
Circuits (Loaded) 36
Circuits (maximum) 0
Gender N/A
Lock to Mating Part Yes
Material - Plating Mating N/A
Net Weight 10600.000/mg
Orientation Vertical
Packaging Type Bag
Panel Mount N/A
Pitch - Mating Interface N/A
Polarized to Mating Part Yes
Temperature Range - Operating -55° to +125°C
Termination Interface: Style N/A
Waterproof / Dustproof Yes
Waterproof / Dustproof Type IP65

Electrical
Current - Maximum per Contact 12.0A

Material Info

Reference - Drawing Numbers
Application Specification AS-58696-004-001, AS-58696-005-001, AS-58696-006-001
Product Specification PS-58691-004-001
Sales Drawing SD-51201-002-001

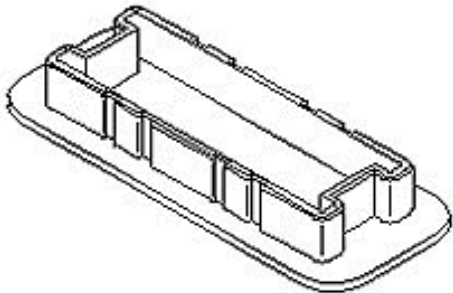

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[51201 Series](#)

Use With
5869100*0 Panel Mount Bracket

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[51201-0001](#)