

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0513532400

Status:


Active

Overview:

MicroClasp Wire-to-Board System

Description:

2.00mm Pitch MicroClasp Wire-to-Board Receptacle Housing, Positive Lock, Dual Row, 24 Circuits, White

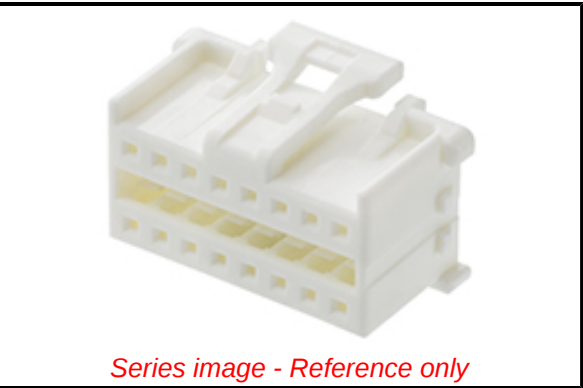

Documents:

3D Model (PDF)

3D Model

Drawing (PDF)

Product Specification PS-51353-003-001 (PDF)

Application Specification 561340000-AS-000 (PDF)

Packaging Specification SPK-51353-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	51353
Application	Signal, Wire-to-Board
Overview	MicroClasp Wire-to-Board System
Product Name	MicroClasp
UPC	756054235836
Physical	
Circuits (maximum)	24
Color - Resin	White
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1123.600/mg
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Application Specification	561340000-AS-000
Packaging Specification	SPK-51353-001-001
Product Specification	PS-51353-003-001
Sales Drawing	SD-51353-002-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

Green Image

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free Status

Low-Halogen

For more information, please visit

Contact US

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

51353 Series

Mates With

MicroClasp Vertical Header 501844
 MicroClasp Vertical Header with Kinked PC Tails 55917
 MicroClasp Right Angle Header 55959

Use With

MicroClasp TPA Retainer 500638
 Crimp Terminal 56134
 MicroClasp Pre-Crimped Leads 797581001 , 797581002

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[51353-2400](#)