

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0520441645
Status: Active
Overview: FFC-FPC (Through-Hole)
Description: FFC/FPC Connector, Non-ZIF, Right-Angle, Top Contact Style Receptacle, 16 Circuits

Documents:
3D Model Product Specification PS-52044-002-001 (PDF)
Drawing (PDF) RoHS Certificate of Compliance (PDF)

Agency Certification
UL E29179


General
Product Family FFC/FPC Connectors
Series 52044
Overview FFC-FPC (Through-Hole)
Product Name Non-ZIF
UPC 800753572485

Physical
Circuits (Loaded) 16
Contact Position Top
Entry Angle 90° Angle
Flammability 94V-0
Mated Height 5.10mm
Net Weight 1401.800/mg
Number of Rows 1
Orientation Right Angle
PC Tail Length 3.50mm
PCB Retention None
Packaging Type Tray
Pitch - Mating Interface 1.25mm
Polarized to PCB Yes
Stackable No
Surface Mount Compatible (SMC) No
Temperature Range - Operating -40°C to +85°C
Termination Interface: Style Through Hole
Wire/Cable Type FFC/FPC

Electrical
Current - Maximum per Contact 0.5A, 1.0A
Voltage - Maximum 200V

Material Info

Reference - Drawing Numbers
Product Specification PS-52044-002-001
Sales Drawing SD-52044-**45

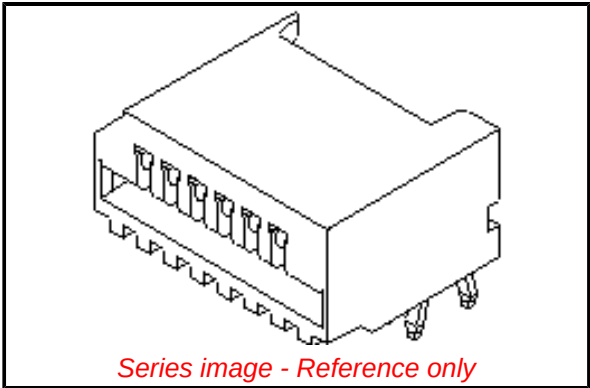

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/30/2017 (7 July
2017)
Halogen-Free
Status
Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
52044 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[52044-1645](#)