

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0520451345
Status: Active
Overview: FFC-FPC (Through-Hole)
Description: FFC/FPC Connector, Non-ZIF, Vertical Receptacle, 13 Circuits

Documents:
[3D Model](#) [Product Specification PS-52045-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
UL E29179


General
Product Family FFC/FPC Connectors
Series 52045
Overview FFC-FPC (Through-Hole)
Product Name Non-ZIF
UPC 800753571808

Physical
Circuits (Loaded) 13
Color - Resin Gray
Contact Position N/A
Entry Angle Vertical
Mated Height 8.00mm
Material - Metal Phosphor Bronze
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Polyester
Net Weight 1114.600/mg
Number of Rows 1
Orientation Vertical
PC Tail Length 3.50mm
PCB Retention None
Packaging Type Tray
Pitch - Mating Interface 1.25mm
Plating min - Mating 0.914µm
Plating min - Termination 0.914µm
Polarized to PCB Yes
Stackable No
Surface Mount Compatible (SMC) No
Temperature Range - Operating -40°C to +85°C
Termination Interface: Style Through Hole - Kinked Pin
Wire/Cable Type FFC/FPC

Electrical
Current - Maximum per Contact 1.0A
Voltage - Maximum 200V

Material Info

Reference - Drawing Numbers
Product Specification PS-52045-001
Sales Drawing SD-52045-**45

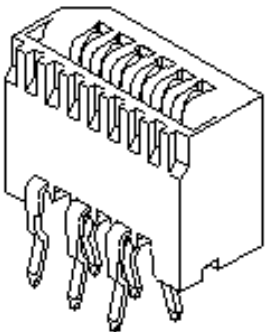

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - ED/30/2017 (7 July 2017) Halogen-Free Status Not Low-Halogen Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS Green Image ELV Not Relevant RoHS Phthalates Not Contained
--	--

Search Parts in this Series
52045 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[52045-1345](#)