

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0520453745
Status: Active
Overview: FFC-FPC (Through-Hole)
Description: FFC/FPC Connector, Non-ZIF, Vertical Receptacle, 37 Circuits

Documents:
[3D Model](#) [Product Specification PS-52045-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
UL E29179


General
Product Family FFC/FPC Connectors
Series 52045
Overview FFC-FPC (Through-Hole)
Product Name Non-ZIF
UPC 800753571730

Physical
Circuits (Loaded) 37
Color - Resin Gray
Contact Position N/A
Entry Angle Vertical
Mated Height 8.00mm
Material - Metal Phosphor Bronze
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Polyester
Net Weight 2856.000/mg
Number of Rows 1
Orientation Vertical
PC Tail Length 3.50mm
PCB Retention None
Packaging Type Tray
Pitch - Mating Interface 1.25mm
Plating min - Mating 0.914µm
Plating min - Termination 0.914µm
Polarized to PCB Yes
Stackable No
Surface Mount Compatible (SMC) No
Temperature Range - Operating -40°C to +85°C
Termination Interface: Style Through Hole - Kinked Pin
Wire/Cable Type FFC/FPC

Electrical
Current - Maximum per Contact 1.0A
Voltage - Maximum 200V

Material Info

Reference - Drawing Numbers
Product Specification PS-52045-001
Sales Drawing SD-52045-**45

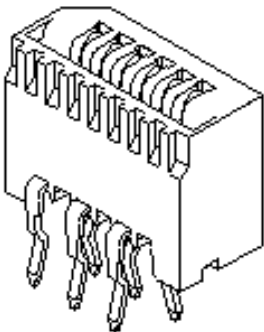

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ED/30/2017 (7 July
2017)
Halogen-Free
Status
Not Low-Halogen
**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
52045 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[52045-3745](#)