

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0524181910

Status:


Active

Overview:

SlimStack Board-to-Board Connectors

Description:

2.00mm Pitch SlimStack Board-to-Board Receptacle, Right-Angle, Single Row, Friction Lock, 19 Circuits

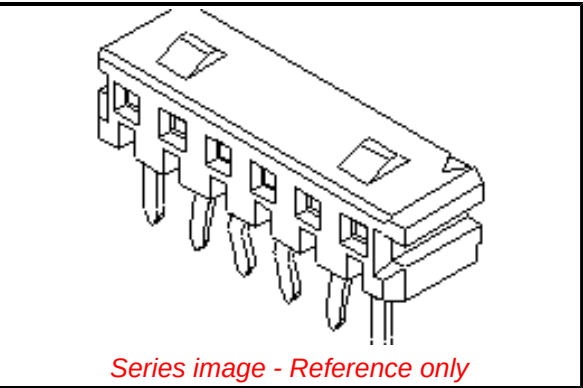

Documents:	
3D Model	Product Specification PS-52418-003-001 (PDF)
Drawing (PDF)	Packaging Specification 524189200-SPK-200 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	PCB Receptacles
Series	52418
Application	Board-to-Board, Signal
Overview	SlimStack Board-to-Board Connectors
Product Name	SlimStack
UPC	800753756045
Physical	
Circuits (Loaded)	19
Circuits (maximum)	19
Color - Resin	Natural
Durability (mating cycles max)	30
Glow-Wire Capable	No
Mated Height	3.95mm
Mated Width	6.00mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	863.100/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Tray
Pitch - Mating Interface	2.00mm
Plating min - Mating	0.914µm
Plating min - Termination	0.914µm
Polarized to PCB	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Through Hole - Kinked Pin
Electrical	
Current - Maximum per Contact	1.5A
Voltage - Maximum	125V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	524189200-SPK-200
Product Specification	PS-52418-003-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)4578-DC (25 June 2020)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

52418 Series

Mates With

53290

This document was generated on 08/25/2020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[52418-1910](#)