

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0524372133

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 21 Circuits, Tin-Silver-Bismuth Plating

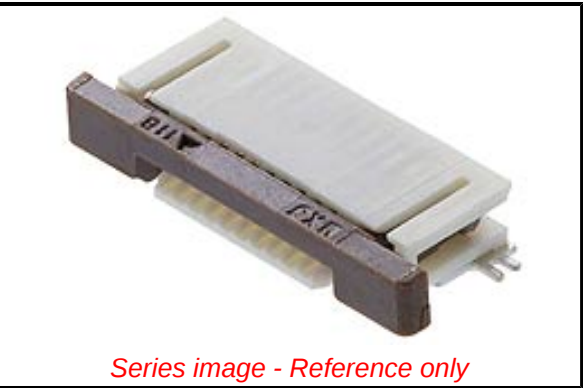

Series image - Reference only

Documents:

- [Drawing \(PDF\)](#)

[3D Model](#)

[3D Model \(PDF\)](#)

[Product Specification PS-52437-028-001 \(PDF\)](#)

[Packaging Specification SPK-52437-001-001 \(PDF\)](#)
- [Datasheet \(PDF\)](#)

[Product Guide \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Reference Guide \(PDF\)](#)

Agency Certification

UL

E29179

General

Product Family

Series

Overview

Product Name

Series Name

UPC

FFC/FPC Connectors

52437

Easy-On FFC FPC Connectors

Easy-On

Slider

887191292960

Physical

Actuator Type

Circuits (Loaded)

Color - Resin

Contact Position

Durability (mating cycles max)

Flammability

Material - Metal

Material - Plating Mating

Material - Plating Termination

Material - Resin

Net Weight

Number of Rows

Orientation

PC Tail Length

PCB Locator

PCB Mounting

PCB Retention

Packaging Type

Pitch - Mating Interface

Pitch - Termination Interface

Polarized to PCB

Stackable

Surface Mount Compatible (SMC)

Temperature Range - Operating

Wire/Cable Type

Slider

21

Natural

Bottom

20

94V-0

Phosphor Bronze

Tin-Silver-Bismuth

Tin-Silver-Bismuth

Nylon

286.555/mg

1

Right Angle

2.00mm

No

Surface Mount

None

Embossed Tape on Reel

0.50mm

0.50mm

Yes

No

N/A

-40° to +85°C

FFC/FPC

Electrical

Current - Maximum per Contact

Voltage - Maximum

0.5A

50V

Material Info

Reference - Drawing Numbers

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

52437 Series

Mates With

Premo-Flex FFC Cable [15166](#) , [98266](#) ,
[15266](#) , [15366](#)

Packaging Specification
Product Specification
Sales Drawing

SPK-52437-001-001
PS-52437-028-001
SD-52437-023-001

This document was generated on 07/02/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[52437-2133](#)