

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0528080471

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, with Pick-and-Place Polyimide Tape, 4 Circuits

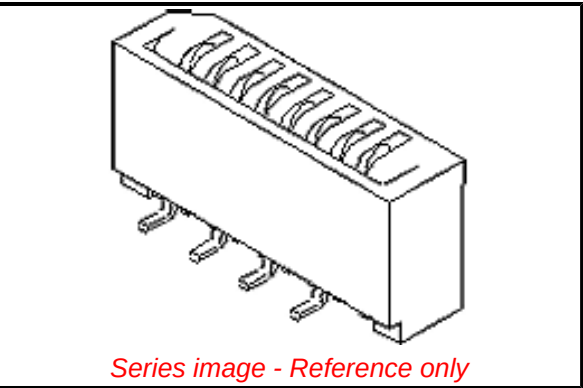

|                                |                                                              |
|--------------------------------|--------------------------------------------------------------|
| Documents:                     |                                                              |
| <a href="#">3D Model</a>       | <a href="#">Product Specification PS-52808-004-001 (PDF)</a> |
| <a href="#">Drawing (PDF)</a>  | <a href="#">Packaging Specification 528089200-200 (PDF)</a>  |
| <a href="#">3D Model (PDF)</a> | <a href="#">RoHS Certificate of Compliance (PDF)</a>         |

|                                |                                |
|--------------------------------|--------------------------------|
| Agency Certification           |                                |
| UL                             | E29179                         |
| General                        |                                |
| Product Family                 | FFC/FPC Connectors             |
| Series                         | 52808                          |
| Overview                       | Easy-On FFC FPC Connectors     |
| Product Name                   | Easy-On                        |
| UPC                            | 822348136025                   |
| Physical                       |                                |
| Actuator Type                  | Non-ZIF                        |
| Circuits (Loaded)              | 4                              |
| Circuits (maximum)             | 4                              |
| Color - Resin                  | Natural                        |
| Contact Position               | N/A                            |
| Durability (mating cycles max) | 10                             |
| Mated Height                   | 5.05mm                         |
| Material - Metal               | Phosphor Bronze                |
| Material - Plating Mating      | Tin-Bismuth                    |
| Material - Plating Termination | Tin-Bismuth                    |
| Material - Resin               | High Temperature Thermoplastic |
| Net Weight                     | 154.100/mg                     |
| Number of Rows                 | 1                              |
| Orientation                    | Vertical                       |
| PCB Locator                    | No                             |
| PCB Mounting                   | Surface Mount                  |
| PCB Retention                  | None                           |
| Packaging Type                 | Embossed Tape on Reel          |
| Pitch - Mating Interface       | 1.00mm                         |
| Pitch - Termination Interface  | 1.00mm                         |
| Polarized to PCB               | No                             |
| Stackable                      | No                             |
| Surface Mount Compatible (SMC) | Yes                            |
| Temperature Range - Operating  | -20° to +80°C                  |
| Wire/Cable Type                | FFC/FPC                        |
| Electrical                     |                                |
| Current - Maximum per Contact  | 0.5A                           |
| Voltage - Maximum              | 125V                           |
| Material Info                  |                                |
| Reference - Drawing Numbers    |                                |
| Packaging Specification        | 528089200-200                  |
| Product Specification          | PS-52808-004-001               |

|                                                               |               |
|---------------------------------------------------------------|---------------|
| EU ELV                                                        |               |
| Not Relevant                                                  |               |
| EU RoHS                                                       | China RoHS    |
| Compliant                                                     |               |
| REACH SVHC                                                    |               |
| Not Contained Per - D(2021)4569-DC (8 July 2021)              |               |
| Halogen-Free                                                  |               |
| Status                                                        |               |
| Not Low-Halogen                                               |               |
| For more information, please visit <a href="#">Contact US</a> |               |
| China ROHS                                                    | Green Image   |
| ELV                                                           | Not Relevant  |
| RoHS Phthalates                                               | Not Contained |

Search Parts in this Series

52808 Series

Sales Drawing

SD-52808-025-001, SD-52808-025-002,  
SD-52808-026-001, SD-52808-026-002,  
SD-52808-026-003, SD-52808-026-004,  
SD-52808-026-005, SD-52808-026-006

This document was generated on 09/23/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[52808-0471](#)