

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0533750610

Status:


Active

Overview:

Mini-Lock Wire-to-Board Connector System

Description:

2.50mm Pitch, Mini-Lock PCB Header, Single Row, Vertical, Through Hole with Kinked Pins, Tin Plating, Positive Lock, 6 Circuits, Bag, 3.40mm PC Tail Length

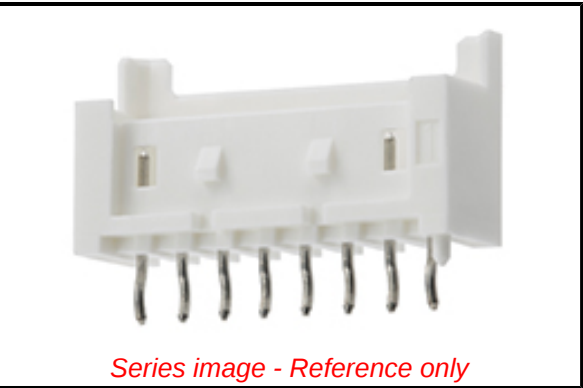

Series image - Reference only

Documents:

- [Drawing \(PDF\)](#)
- [3D Model \(PDF\)](#)
- [3D Model](#)
- [Product Specification 511630000-PS-000 \(PDF\)](#)
- [Product Specification 511631000-PS-000 \(PDF\)](#)
- [Product Specification PS-51103-005-001 \(PDF\)](#)
- [Packaging Specification 533759200-SPK-200 \(PDF\)](#)
- [Packaging Specification SPK-53375-001-001 \(PDF\)](#)
- [Packaging Specification SPK-53375-001-002 \(PDF\)](#)
- [Datasheet \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	PCB Headers
Series	53375
Application	Signal, Wire-to-Board
Overview	Mini-Lock Wire-to-Board Connector System
Product Name	Mini-Lock
UPC	800753563650

Physical

Breakaway	No
Circuits (Loaded)	6
Circuits (maximum)	6
Color - Resin	Natural
Durability (mating cycles max)	30
First Mate / Last Break	No
Flammability	94V-0
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	741.800/mg
Number of Rows	1
Orientation	Vertical
PC Tail Length	3.40mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Bag
Pitch - Mating Interface	2.50mm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Shrouded	Fully
Stackable	No
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Through Hole - Kinked Pin

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

53375 Series

Mates With

Mini-Lock Receptacle [51163](#) . Mini-Lock
Cable Assembly [15137](#)

Electrical

Current - Maximum per Contact	3.0A
Voltage - Maximum	250V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Packaging Specification	533759200-SPK-200, SPK-53375-001-001, SPK-53375-001-002
Product Specification	511630000-PS-000, 511631000-PS-000, PS-51103-005-001
Sales Drawing	533750000-SD-000, SD-53375-001-001

This document was generated on 09/03/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[53375-0610](#)