

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0533751010

Status:


Active

Overview:

Mini-Lock Wire-to-Board Connector System

Description:

2.50mm Pitch, Mini-Lock PCB Header, Single Row, Vertical, Through Hole with Kinked Pins, Tin Plating, Positive Lock, 10 Circuits, Bag, 3.40mm PC Tail Length

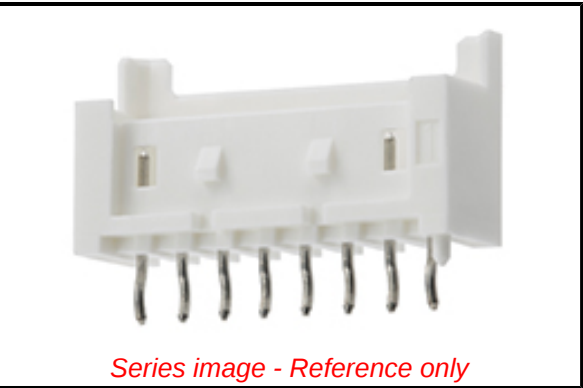

Documents:	
3D Model (PDF)	Product Specification PS-51103-005-001 (PDF)
Drawing (PDF)	Packaging Specification 533759200-SPK-200 (PDF)
3D Model	Packaging Specification SPK-53375-001-001 (PDF)
Product Specification 511630000-PS-000 (PDF)	Datasheet (PDF)
Product Specification 511631000-PS-000 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	PCB Headers
Series	53375
Application	Signal, Wire-to-Board
Overview	Mini-Lock Wire-to-Board Connector System
Product Name	Mini-Lock
UPC	800754235181
Physical	
Breakaway	No
Circuits (Loaded)	10
Circuits (maximum)	10
Color - Resin	Natural
Durability (mating cycles max)	30
First Mate / Last Break	No
Flammability	94V-0
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	1099.000/mg
Number of Rows	1
Orientation	Vertical
PC Tail Length	3.40mm
PCB Locator	Yes
PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Bag
Pitch - Mating Interface	2.50mm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Shrouded	Fully
Stackable	No
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Through Hole - Kinked Pin
Electrical	

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
53375 Series
Mates With
Mini-Lock Receptacle 51163 . Mini-Lock Cable Assembly 15137

Current - Maximum per Contact
Voltage - Maximum

3.0A
250V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Packaging Specification
Product Specification

Sales Drawing

533759200-SPK-200, SPK-53375-001-001
511630000-PS-000, 511631000-PS-000,
PS-51103-005-001
533750000-SD-000, SD-53375-001-001

This document was generated on 09/08/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[53375-1010](#)