


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0533981471](#)
Status: **Active**
Overview: [PicoBlade Connector System](#)
Description: 1.25mm Pitch, PicoBlade PCB Header, Single Row, Vertical, Surface Mount, Tin (Sn) Plating, Friction Lock, 14 Circuits, Tape and Reel, 0.60mm PC Tail Length

Documents:

3D Model	Product Specification PS-51021-024-001 (PDF)
3D Model (PDF)	Application Specification 510210000-AS-000 (PDF)
Drawing (PDF)	Packaging Specification SPK-53398-002-001 (PDF)
Product Specification 510211024-PS-000 (PDF)	RoHS Certificate of Compliance (PDF)

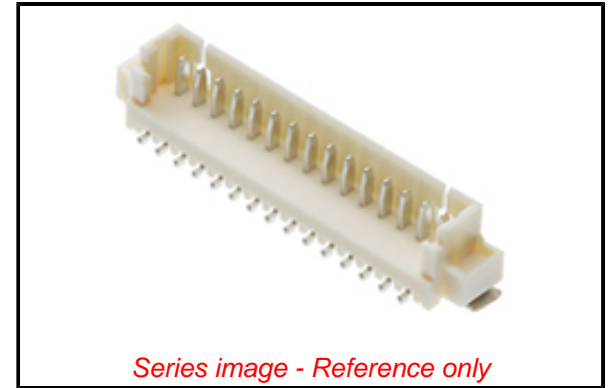

Agency Certification

UL E29179

General

Product Family	PCB Headers
Series	53398
Application	Signal, Wire-to-Board
Current Derating Order No	987651-3691
Overview	PicoBlade Connector System
Product Name	PicoBlade
UPC	822348164417

Physical

Breakaway	No
Circuits (Loaded)	14
Circuits (maximum)	14
Color - Resin	Natural
Durability (mating cycles max)	30
First Mate / Last Break	No
Flammability	94V-0
Glow-Wire Capable	No
Guide to Mating Part	No
Lock to Mating Part	Yes
Mated Height	5.70mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	393.500/mg
Number of Rows	1
Orientation	Vertical
PC Tail Length	0.60mm
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	1.25mm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Shrouded	Partial
Stackable	No
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount

Electrical

Current - Maximum per Contact 1.0A

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[53398 Series](#)

Mates With

PicoBlade Housing [51021](#)
PicoBlade
Cable Assembly [15134](#)

Voltage - Maximum

125V

Material Info

Reference - Drawing Numbers

Application Specification

510210000-AS-000

Packaging Specification

SPK-53398-002-001

Product Specification

510211024-PS-000, PS-51021-024-001

Sales Drawing

533980000-SD-000

This document was generated on 08/10/2020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[53398-1471](#)