

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0534812079](#)
Status: **Active**
Overview: SlimStack™ 0.635mm Pitch Board-to-Board Connectors
Description: 0.635mm Pitch SlimStack Plug, Surface Mount, Dual Row, Vertical Stacking, 7.00mm Stacking Heights, 200 Circuits, Tube Packaging

Documents:

[3D Model](#) [Product Specification PS-52760-015-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification 527600000-000 \(PDF\)](#)

Agency Certification

UL E29179

General


Product Family PCB Headers
 Series [53481](#)
 Application Board-to-Board, Signal
 Comments Stacking-Type
 Overview [SlimStack™ 0.635mm Pitch Board-to-Board Connectors](#)
 Product Name SlimStack
 UPC 822348168484

Physical

Breakaway No
 Circuits (Loaded) 200
 Circuits (maximum) 200
 Color - Resin Natural
 Durability (mating cycles max) 50
 First Mate / Last Break No
 Flammability 94V-0
 Glow-Wire Compliant No
 Guide to Mating Part No
 Keying to Mating Part None
 Lock to Mating Part Yes
 Mated Height 7.00mm
 Material - Metal Phosphor Bronze
 Material - Plating Mating Gold
 Material - Plating Termination Tin
 Net Weight 1746.200/mg
 Number of Rows 2
 Orientation Vertical
 PCB Locator Yes
 PCB Retention Yes
 Packaging Type Tube
 Pitch - Mating Interface 0.64mm
 Plating min - Mating 0.254µm
 Plating min - Termination 1.016µm
 Polarized to PCB Yes
 Shrouded Fully
 Stackable No
 Temperature Range - Operating -55°C to +105°C
 Termination Interface: Style Surface Mount

Electrical

Current - Maximum per Contact 0.5A
 Voltage - Maximum 100V

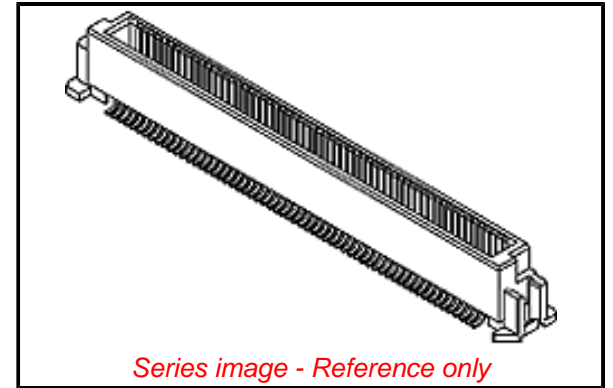

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/30/2017 (7 July
 2017)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[53481 Series](#)

Mates With

SlimStack Receptacle [52760](#) , [52837](#) ,
[52885](#) , [52901](#)

Material Info

Reference - Drawing Numbers

Product Specification

Sales Drawing

527600000-000, PS-52760-015-001

SD-53481-**79, SD-53481-003

This document was generated on 12/06/2017

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[53481-2079](#)