

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0541323333

Status:

Active

Overview:

Easy-On FFC FPC Connectors

Description:

Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 33 Circuits, Tin-Silver-Bismuth Plating

Documents:

- [3D Model \(PDF\)](#)[Datasheet \(PDF\)](#)
- [3D Model](#)[Product Guide \(PDF\)](#)
- [Drawing \(PDF\)](#)[RoHS Certificate of Compliance \(PDF\)](#)
- [Product Specification PS-54132-062-001 \(PDF\)](#)[Reference Guide \(PDF\)](#)
- [Packaging Specification SPK-54132-001-001 \(PDF\)](#)

Agency Certification

UL

E29179

General

Product Family

FFC/FPC Connectors

Series

54132

Overview

Easy-On FFC FPC Connectors

Product Name

Easy-On

Series Name

Slider

UPC

887191270630

Physical

Actuator Type

Slider

Circuits (Loaded)

33

Color - Resin

Black, Natural

Contact Position

Bottom

Durability (mating cycles max)

20

Flammability

94V-0

Mated Height

2.00mm

Material - Metal

Phosphor Bronze

Material - Plating Mating

Tin-Silver-Bismuth

Material - Plating Termination

Tin-Silver-Bismuth

Material - Resin

Nylon

Net Weight

384.400/mg

Number of Rows

1

Orientation

Right Angle

PC Tail Length

2.00mm

PCB Locator

No

PCB Mounting

Surface Mount

PCB Retention

None

Packaging Type

Embossed Tape on Reel

Pitch - Mating Interface

0.50mm

Pitch - Termination Interface

0.50mm

Polarized to PCB

Yes

Stackable

No

Surface Mount Compatible (SMC)

N/A

Temperature Range - Operating

-40° to +85°C

Wire/Cable Type

FFC/FPC

Electrical


Current - Maximum per Contact

0.5A

Voltage - Maximum

50V

Material Info

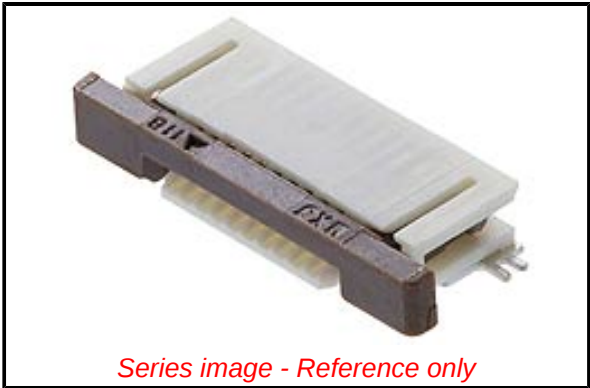

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

54132 Series

Mates With

Premo-Flex FFC Cable [15166](#) , [98266](#) ,
[15266](#) , [15366](#)

Reference - Drawing Numbers

Packaging Specification	SPK-54132-001-001
Product Specification	PS-54132-062-001
Sales Drawing	541320000-000, 541321000-000

This document was generated on 07/07/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

54132-3333