

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0545520902](#)
Status: **Active**
Overview: SlimStack™ 0.40mm (.016") Pitch Headers and Receptacles
Description: 0.40mm Pitch Board-to-Board SlimStack™ Receptacle, SMT, Dual Row, with Plastic Pegs, Right Angle, 90 Circuits

Documents:

[3D Model](#) [Packaging Specification SPK-54552-017 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-54552-023 \(PDF\)](#)

General

Product Family	PCB Receptacles
Series	54552
Application	Board-to-Board, Signal
Overview	SlimStack™ 0.40mm (.016") Pitch Headers and Receptacles
Product Name	SlimStack™

Physical

Circuits (Loaded)	90
Color - Resin	Brown
Durability (mating cycles max)	30
Glow-Wire Compliant	No
Mated Height	4.25mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Number of Rows	2
Orientation	Right Angle
PCB Locator	Yes
PCB Retention	None
PCB Thickness - Recommended	1.60mm
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.40mm
Polarized to PCB	No
Temperature Range - Operating	-40°C to +85°C
Termination Interface: Style	Surface Mount


Electrical

Current - Maximum per Contact	0.3A
Voltage - Maximum	30V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Packaging Specification	SPK-54552-017
Product Specification	PS-54552-023
Sales Drawing	SD-54552-023, SD-54552-024

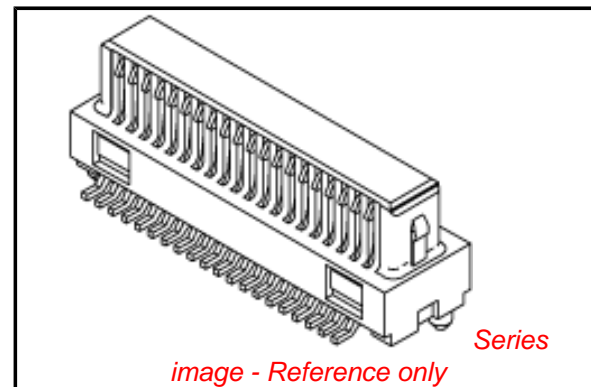

EU RoHS

ELV and RoHS Compliant
REACH SVHC Not Reviewed
Low-Halogen Status Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[54552Series](#)

Mates With

[55394 PCB Header](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[54552-0902](#)