


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0547220504](#)
Status: **Active**
Overview: SlimStack Board-to-Board/Board-to-FPC Connectors
Description: 0.50mm Pitch SlimStack Receptacle, Surface Mount, Dual Row, Vertical, 1.50mm Stacking Height, Lower Circuit Size Version, 50 Circuits, Gold Plating with Nickel Barrier Plating Between Contact and Tail

Documents:
[3D Model](#) [Application Specification 547220000-A00 \(PDF\)](#)
[Drawing \(PDF\)](#) [Packaging Specification SPK-54722-001-002 \(PDF\)](#)
[3D Model \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification PS-54722-010-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification	
UL	E29179
General	
Product Family	PCB Receptacles
Series	54722
Application	Board-to-Board, Signal
Comments	Embossed Tape Reel Height: 380.00mm Gold plating with Nickel plating between contact and tail
Overview	SlimStack Board-to-Board/Board-to-FPC Connectors
Product Name	SlimStack
Series Name	0.5, BB H1.5
UPC	756054574379
Physical	
Circuits (Loaded)	50
Circuits (maximum)	50
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Capable	No
Lock to Mating Part	None
Mated Height	1.50mm
Mated Width	6.00mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	High Temperature Thermoplastic
Net Weight	149.401/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
PCB Retention	None
PCB Thickness - Recommended	1.60mm
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Polarized to PCB	No
Surface Mount Compatible (SMC)	N/A
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	50V
Material Info	

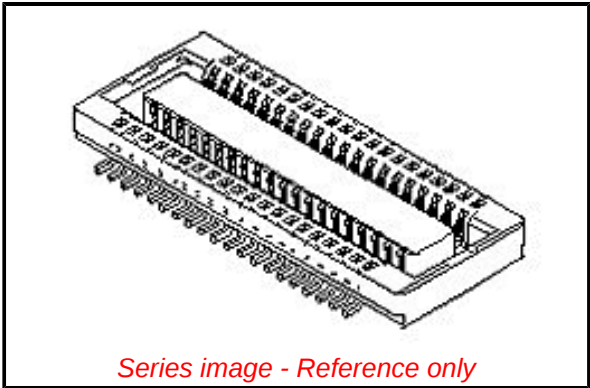

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[54722](#) Series

Mates With
[55560](#) PCB Header

Reference - Drawing Numbers

Application Specification	547220000-A00
Packaging Specification	SPK-54722-001-002
Product Specification	PS-54722-010-001
Sales Drawing	SD-54722-011-001, SD-54722-012-001

This document was generated on 01/24/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[54722-0504](#)