

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0561618081

Status:

Active

Overview:

DuraClik Connector System

Description:

2.00mm Pitch DuraClik Crimp Terminal, Female, 22-26 AWG, Gold (Au) Plating, Reel

Documents:

Drawing (PDF)

Product Specification PS-502351-002-001 (PDF)

Application Specification AS-54992-006-001 (PDF)

Packaging Specification 561619200-200 (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Application

Crimp Quality Equipment

Overview

Packaging Alternative

Product Name

UPC

Crimp Terminals

56161

Automotive, Signal, Wire-to-Board

Yes

DuraClik Connector System

561618181 (Bag)

DuraClik

800756476667

Physical

Gender

Material - Metal

Material - Plating Mating

Material - Plating Termination

Net Weight

Packaging Type

Termination Interface: Style

Wire Insulation Diameter

Wire Size AWG

Wire Size mm²

Female

Phosphor Bronze

Gold

Nickel

18.300/mg

Reel

Crimp or Compression

1.40mm max.

22, 24, 26

N/A

Electrical

Current - Maximum per Contact

Voltage - Maximum

3.0A

125V

Material Info

Reference - Drawing Numbers

Application Specification

Application Tooling Documents

Crimp Specification

Packaging Specification

Product Specification

Sales Drawing

AS-54992-006-001


571753710ATS-000, 571753710ATS-J-000

CS-56161-003-001

561619200-200

PS-502351-002-001

SD-56161-002-001

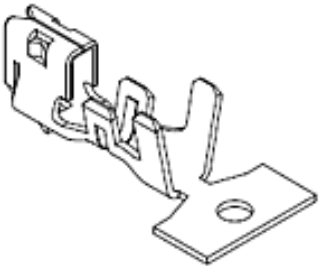

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

56161 Series

Use With

DuraClik Receptacle Housing 502351

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

FineAdjust Applicator for 2.0 Wire-to-Board Crimp Receptacle Terminal and SMEC Crimp Receptacle Terminals, 22-26 AWG and AVSS 0.3 Wires PremiumGrade Hand Crimp Tool for Micro-Latch, DuraClik, and

2037021900

638235100

Servo Motor Encoder Female Terminals, 22-26 AWG T2 Terminator Die		<u>638528000</u>
Japan		
Description	Product #	
Applicator for M211A Bench Press, 22-30 AWG Wire	<u>571753000</u>	
S-1 Applicator for DuraClik and Mi II Terminals, 22-26 AWG	<u>571753710</u>	

This document was generated on 09/23/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[56161-8081](#)