

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0563870000](#)
Status: **Active**
Overview: [HMC Heavy Duty Rectangular Connectors](#)
Description: HMC Rectangular Industrial Wire-to-Wire Bracket Cover, 48 and 72 Circuits, External Thread, PG36


Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-58719-006-001 \(PDF\)](#)

General	
Product Family	I/O Connectors
Series	56387
Application	Wire-to-Wire
Component Type	Wire-to-Wire Bracket Cover
Overview	HMC Heavy Duty Rectangular Connectors
Product Name	HMC
Type	N/A
UPC	800756052243
Physical	
Circuits (Loaded)	N/A
Lock to Mating Part	Yes
Material - Plating Mating	N/A
Net Weight	257000.000/mg
Orientation	Vertical
Packaging Type	Bag
Panel Mount	N/A
Pitch - Mating Interface	N/A
Polarized to Mating Part	N/A
Temperature Range - Operating	-55° to +125°C
Termination Interface: Style	N/A
Waterproof / Dustproof	Yes
Waterproof / Dustproof Type	IP65
Electrical	
Current - Maximum per Contact	N/A

Material Info

Reference - Drawing Numbers

Product Specification	PS-58719-006-001
Sales Drawing	SD-56387-002-001

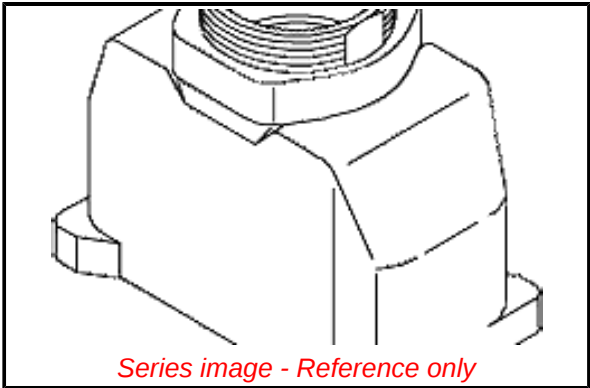

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(b)-II

REACH SVHC

Contained Per -
D(2021)4569-DC (8
July 2021)
Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[56387](#) Series

Use With

[58866](#) End Bell Cap Assembly, [58719](#)
Panel-Mount Bracket

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

56387-0000