

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0588660003

Status:


Active

Overview:

HMC Heavy Duty Rectangular Connectors

Description:

HMC Rectangular Industrial End Bell Cap Assembly, PG36, 20.00-25.00mm dia. Wire Size, Orange Bush, for External Threaded Hoods

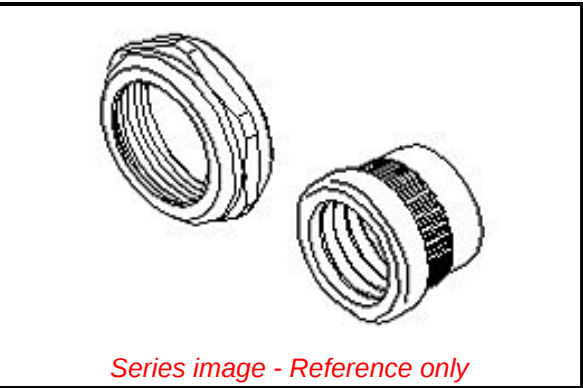

Documents:

3D Model

3D Model (PDF)

Drawing (PDF)

Product Specification PS-58719-005-001 (PDF)

Product Specification PS-58719-006-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	I/O Connectors
Series	58866
Application	Panel-Mount
Component Type	Bell Cap Assembly
Overview	HMC Heavy Duty Rectangular Connectors
Product Name	HMC
Type	N/A
UPC	800756393605
Physical	
Circuits (Loaded)	48, 72
Color - Resin	Orange
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	N/A
Material - Resin	PVC
Net Weight	156.000/g
Orientation	Vertical
Packaging Type	Bag
Panel Mount	N/A
Pitch - Mating Interface	N/A
Polarized to Mating Part	Yes
Termination Interface: Style	N/A
Waterproof / Dustproof	Yes
Waterproof / Dustproof Type	IP65
Electrical	
Current - Maximum per Contact	N/A
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-58719-005-001, PS-58719-006-001
Sales Drawing	SD-58866-002-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2021)4569-DC (8 July 2021)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

58866 Series

Use With

587230010 Hood

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[58866-0003](#)