

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0621001960

Status:

Active

Overview:

Application Tooling

Description:

MiniDIMM Memory Card Insertion Tool


Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207123
Comments	See Tooling Specification (PDF) Above
Function	Insertion
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	MiniDIMM
Tool Type	Insertion Hand Tool
UPC	887191250137
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers	
Application Tooling Documents	ATS-621001960

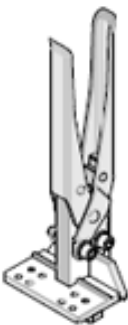

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

207123 Series

Use With

78035 , 78359 MiniDIMM 0.60mm Pitch DDR/DDR2/DDR3 Sockets, 200, 240, and 244 circuits, reverse angle, 22½° and 25°.

Application Tooling Description	FAQ Product #
0.60mm Pitch miniDIMM DDR2 Socket, Surface Mount, 22.5° Reverse Angle, 0.76µm Gold (Au) Plating, Off-White Latches, with Pick-and-Place Cap, 244 Circuits, 1.8V Voltage Key, Lead-Free	780350001
0.60mm Pitch miniDIMM DDR Socket, Surface	780350202

Mount, 22.5°
Reverse Angle,
0.76µm Gold (Au)
Plating, Off-White
Latches, with Pick-
and-Place Cap,
200 Circuits, 2.5V
Voltage Key, Lead-
Free
0.60mm Pitch 780350301
miniDIMM DDR3
Socket, Surface
Mount, 22.5°
Reverse Angle,
0.76µm Gold (Au)
Plating, Off-White
Latches, 244
Circuits,1.5V Voltage
Key, Lead-Free
1.00mm Pitch DDR3 783590001
DIMM Socket, Very
Low Profile, 25°
Angle, Through Hole,
with Beveled Metal
Pins, Black Housing
and Latches, 0.76µm
Gold (Au) Plating,
2.79mm Solder Tail
Length, 1.57mm
PCB Thickness, 1.5V
Center Voltage Key,
1.00mm Pitch DDR3 783590111
DIMM Socket, Very
Low Profile, 25°
Angle, Through Hole,
with Beveled Metal
Pins, Black Housing
and Latches, 0.76µm
Gold (Au) Plating,
4.00mm Solder Tail
Length, 2.59mm
PCB Thickness, 1.5V
Center Voltage Key,

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[62100-1960](#)