

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0621007800

Status:

Active

Overview:

Application Tooling

Description:

Removal Tool for Vertical Signal Modules


Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207121
Comments	See Tooling Specification (PDF) Above
Function	Extraction
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	EXTreme Ten60Power
Tool Type	Extraction Hand Tool
UPC	883906317973
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers	
Application Tooling Documents	ATS-621007800-001

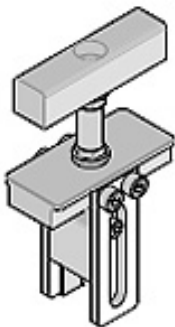

Series image - Reference only

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207121 Series

Use With

Ten60 Vertical Signal Modules, 46534 and 46724 Series. Ten60 Vertical Receptacle Assemblies, 46562 Series

Application Tooling Description	FAQ Product #
TEN50, 15-ckt VERT RECPT. SIGNAL MODULE	465341015
TEN60, V-RECPT SIGNAL HSG 18-CKT	465341018
TEN60, V-RECPT SIGNAL MODULE 21-CKT	465341021
TEN50, 24ckt VERTICAL SIGNAL MODULE	465341024
TEN60, V-RECPT SIGNAL MODULE 27-CKT	465341027

TEN50 V-RECPT SIGNAL MODULE 30-CKT	<u>465341030</u>
TEN60, V-RECPT SIGNAL MODULE 33-CKT	<u>465341033</u>
TEN60, V-RECPT SIGNAL MODULE 36-CKT	<u>465341036</u>
2.00mm Pitch EXTreme Ten60Power Vertical Receptacle Assembly with Guide Receivers, 10 Signal Circuits, 2 Power Circuits	<u>465621001</u>
2.54mm, 5.50mm Pitch EXTreme Ten60Power Vertical Receptacle Assembly with Guide Receivers, 24 Signal Circuits, 6 Power Circuits	<u>465621003</u>
2.54mm, 5.50mm Pitch EXTreme Ten60Power Vertical Receptacle Assembly with Guide Receivers, 24 Signal Circuits, 4 Power Circuits	<u>465621011</u>
2.54mm, 5.50mm, 7.50mm Pitch EXTreme Ten60Power Vertical Receptacle Assembly with Guide Receivers, 24 Signal Circuits, 7 Power Circuits	<u>465621020</u>
2.54mm, 5.50mm Pitch EXTreme Ten60Power Vertical Receptacle Assembly with Guide Receivers, 3 DC Power Circuits, 33 Signal Circuits, 9 DC Power Circuits, 9 DC Power Circuits	<u>465621035</u>
ten60, VERTICAL RECPT ASSY 6DC-24S-3AC	<u>465621041</u>
2.54mm, 5.50mm Pitch EXTreme Ten60Power Vertical Receptacle Assembly with Guide Receivers, 27 Signal Circuits, 10 Power Circuits	<u>465621073</u>
2.54mm, 5.50mm, 7.50mm Pitch	<u>465621084</u>

EXTreme	
Ten60Power	
Vertical Receptacle	
Assembly with Guide	
Receivers, 3 AC	
Power Circuits, 4 DC	
Power Circuits, 24	
Signal Circuits	
2.54mm, 5.50mm	<u>465621094</u>
Pitch EXTreme	
Ten60Power	
Vertical Receptacle	
Assembly with Guide	
Receivers, 24 Signal	
Circuits, 14 Power	
Circuits	
2.54mm, 5.50mm	<u>465621106</u>
Pitch EXTreme	
Ten60Power	
Vertical Receptacle	
Assembly with Guide	
Receivers, 45 Signal	
Circuits, 18 Power	
Circuits	
2.54mm, 5.50mm	<u>465621117</u>
Pitch EXTreme	
Ten60Power	
Vertical Receptacle	
Assembly with Guide	
Receivers, 24 Signal	
Circuits, 6 Power	
Circuits	
2.54mm, 5.50mm	<u>465621119</u>
Pitch EXTreme	
Ten60Power	
Vertical Receptacle	
Assembly with Guide	
Receivers, 24 Signal	
Circuits, 2 Power	
Circuits	
2.54mm, 5.50mm	<u>465621208</u>
Pitch EXTreme	
Ten60Power	
Vertical Receptacle	
Assembly with Guide	
Receivers, 24 Signal	
Circuits, 8 Power	
Circuits	
2.54mm, 5.50mm	<u>465623001</u>
Pitch EXTreme	
Ten60Power	
Vertical Receptacle	
Assembly with Guide	
Receivers, 24 Signal	
Circuits, 4 Power	
Circuits	
2.54mm, 5.50mm	<u>465623002</u>
Pitch EXTreme	
Ten60Power	
Vertical Receptacle	
Assembly with Guide	
Receivers, 24 Signal	
Circuits, 4 Power	
Circuits	

	2.54mm, 5.50mm	<u>465623003</u>
	Pitch EXTreme	
	Ten60Power	
	Vertical Receptacle	
	Assembly with Guide	
	Receivers, 24 Signal	
	Circuits, 4 Power	
	Circuits	
	2.54mm, 5.50mm	<u>465623004</u>
	Pitch EXTreme	
	Ten60Power Vertical	
	Receptacle with Top	
	Guide Receivers,	
	24 Signal Circuits, 4	
	Power Circuits	
	2.54mm, 5.50mm	<u>465623005</u>
	Pitch EXTreme	
	Ten60Power	
	Vertical Receptacle	
	Assembly with Guide	
	Receivers, 24 Signal	
	Circuits, 6 Power	
	Circuits	
	2.54mm, 5.50mm	<u>465623006</u>
	Pitch EXTreme	
	Ten60Power	
	Vertical Receptacle	
	Assembly with Guide	
	Receivers, 24 Signal	
	Circuits, 6 Power	
	Circuits	
	2.54mm, 5.50mm	<u>465623007</u>
	Pitch EXTreme	
	Ten60Power	
	Vertical Receptacle	
	Assembly with Guide	
	Receivers, 24 Signal	
	Circuits, 6 Power	
	Circuits	
	2.54mm, 5.50mm	<u>465623008</u>
	Pitch EXTreme	
	Ten60Power	
	Vertical Receptacle	
	Assembly with Top	
	Guide Receivers,	
	24 Signal Circuits, 6	
	Power Circuits	
	2.54mm, 5.50mm,	<u>465623010</u>
	7.50mm Pitch	
	EXTreme	
	Ten60Power	
	Vertical Receptacle	
	Assembly with Guide	
	Receivers, 24 Signal	
	Circuits, 7 Power	
	Circuits	
	2.54mm, 5.50mm,	<u>465623011</u>
	7.50mm Pitch	
	EXTreme	
	Ten60Power	
	Vertical Receptacle	
	Assembly with Guide	
	Receivers, 24 Signal	
	Circuits, 7 Power	
	Circuits	

	2.54mm, 5.50mm, 7.50mm Pitch EXTreme Ten60Power Vertical Receptacle with Top Guide Receivers, 24 Signal Circuits, 7 Power Circuits	<u>465623012</u>
	2.54mm, 5.50mm, 7.50mm Pitch EXTreme Ten60Power Vertical Receptacle with Top Guide Receivers, 24 Signal Circuits, 7 Power Circuits	<u>465623013</u>
	7.500mm Pitch EXTreme Ten60Power Vertical Receptacle Assembly , 2 Power Circuits	<u>465629102</u>
	TEN50, VERT. SIGNAL PLUG MODULE, 24-CKT	<u>467240024</u>

This document was generated on 07/30/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[62100-7800](#)