

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0622018603

Status:

Active

Overview:

Application Tooling

Description:

Press-In Tool for Vertical Header 11-Row, 10-Column

Documents:

RoHS Certificate of Compliance (PDF)


General	
Product Family	Application Tooling
Series	207123
Comments	See Tooling Specification (PDF) Above, Press-In Tool
Function	Insertion
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Press-Fit Insertion Tool
UPC	822350334150
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers

Application Tooling Documents

ATS-622018603, TM-622018699

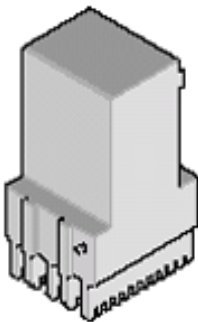

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

207123 Series

Use With

GbX I-Trac Backplane Signal Module, 75705 Series

Application Tooling Description	FAQ Product #
GbX I-Trac Vertical Header Module, 1.85mm by 3.70mm Pitch, Unguided, Dual End Walls, 11 Rows, 10 Columns, 220 Circuits, Mating Pin Length 5.70mm	757051124
GbX I-Trac Vertical Header Module, 1.85mm by 3.70mm Pitch, Left Guide, Right Open, 11 Rows, 10 Columns, 220 Circuits, Mating Pin Length 4.70mm	757053103
GbX I-Trac Vertical Header Module,	757053104

1.85mm by 3.70mm
Pitch, Left Guide,
Right Open, 11
Rows, 10 Columns,
220 Circuits, Mating
Pin Length 5.70mm
GbX I-Trac Vertical 757055103
Header Module,
1.85mm by 3.70mm
Pitch, Right Guide,
Left Open, 11 Rows,
10 Columns, 200
Circuits, Mating Pin
Length 4.70mm

This document was generated on 02/26/2021
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[62201-8603](#)