

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0622018617

Status:

Active

Overview:

Application Tooling

Description:

Press-In Tool for Vertical Header 11-Row, 8-Column


Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207123
Comments	See Tooling Specification (PDF) Above, Press-In Tool
Function	Insertion
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	PremiumGrade
Tool Type	Press-Fit Insertion Tool
UPC	822350873055
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers	
Application Tooling Documents	ATS-622018617, TM-622018699

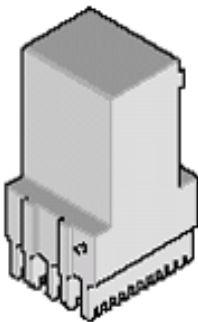

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit	Contact US
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

207123 Series

Use With

GbX I-Trac Backplane Signal Module, 75705 Series

Application Tooling Description	FAQ Product #
GbX I-Trac Vertical Header Module, 1.85mm by 3.70mm Pitch, Unguided, Open Ends, 11 Rows, 8 Columns, 176 Circuits, Mating Pin Length 5.70mm	757051804
GbX I-Trac Vertical Header Module, 1.85mm by 3.70mm Pitch, Left Guide, Right Open, 11 Rows, 8 Columns, 176 Circuits, Key	757053824

Orientation B, Mating
Pin Length 5.70mm
GbX I-Trac Vertical 757055824
Header Module,
1.85mm by 3.70mm
Pitch, Right Guide,
Left Open, 11 Rows,
8 Columns, 176
Circuits, Mating Pin
Length 5.70mm, Key
Orientation B

This document was generated on 05/10/2021
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[62201-8617](#)