

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION


Part Number: [0622018642](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: Right-Angle Power Module Installation Press-In Tool

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Application Tooling
Series	207123
Comments	See Tooling Specification (PDF) Above
Function	Insertion
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	PremiumGrade
Tool Type	Press-Fit Insertion Tool
UPC	800756930640
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers	
Application Tooling Documents	ATS-622018642, TM-622018799

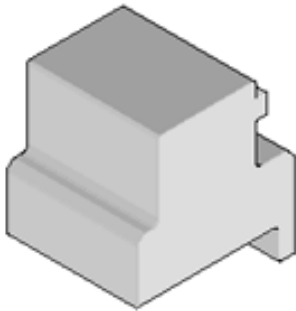

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Not Reviewed REACH SVHC Not Contained Per - ED/108/2014 (17 Dec 2014) Halogen-Free Status Not Relevant For more information, please visit Contact US	China RoHS
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
[207123](#) Series

Use With
Impact Right Angle Power Module, [78213](#) Series

Application Tooling Description	FAQ Product #
Impact 4 Pair, Right-Angle Power Header, Press-Fit, Blade A1 & A2, B1 & B2 Length 6.90mm, LCP, Glass Filled UL94-V0, Black, Tray Packaging, Lead-Free	782131011
Impact 4 Pair Right-Angle Power Header, Press-Fit, Blade A1 & A2, B1 & B2 Length 5.70mm, LCP, Glass Filled	782131022

UL94-V0, Black,
Lead-Free
Impact 4 Pair, Right- [782131033](#)
Angle Power Header,
Press-Fit, Blade
A1 & A2 Length
5.70mm, B1 & B2
Length 6.90mm,
LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free
Impact 4 Pair, Right- [782131044](#)
Angle Power Header,
Press-Fit, Blade
A1 & A2 Length
6.90mm, Blade B1
& B2 Length 5.70,
LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free
Impact 4 Pair, [782481001](#)
Right-Angle Power
Receptacle, Press-
Fit, LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free
Impact 4 Pair, Right- [783491001](#)
Angle Power Header,
Left Hold-Down,
Press-Fit, Module
1: Blade P1 & P2
Length 6.90mm;
LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free
Impact 4 Pair, Right- [783491002](#)
Angle Power Header,
Left Hold-Down,
Press-Fit, Module
1: Blade P1 & P2
Length 5.70mm;
LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free
Impact 4 Pair, Right- [783491003](#)
Angle Power Header,
Left Hold-Down,
Press-Fit, Module
1: Blade P1 & P2
Length 6.90mm
& 5.70mm; LCP,
Glass Filled UL94-
V0, Black, Tray
Packaging, Lead-
Free
Impact 4 Pair, Right- [783491004](#)
Angle Power Header,
Left Hold-Down,
Press-Fit, Module
1: Blade P1 & P2

Length 5.70mm
& 6.90mm; LCP,
Glass Filled UL94-
V0, Black, Tray
Packaging, Lead-
Free

Impact 4 Pair, Right- [783491011](#)
Angle Power Header,
2 Modules with Left
Hold-Down, Module
1: Blade P1 & P2,
Length 6.90mm;
Module 2: Blade
P1 & P2, Length
6.90mm; Press-Fit,
LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free

Impact 4 Pair Right- [783491041](#)
Angle Power Header,
2 Modules with
Left Hold-Down,
Module 1: Blade P1
& P2, Length 6.90
& 6.90mm; Module
2: Blade P1 & P2
Length 5.70mm &
6.90mm, Press-Fit,
LCP, Glass Filled
UL94-V

Impact 4 Pair, Right- [783491044](#)
Angle Power Header,
2 Modules with
Left Hold-Down,
Module 1: Blade P1
& P2 Length 5.70
& 6.90mm; Module
2: Blade P1 & P2
Length 5.70mm &
6.90mm, Press-Fit,
LCP, Glass Filled
UL94-V

Impact 4 Pair, Right- [783492001](#)
Angle Power Header,
Right Hold-Down,
Module 1: Blade
P1 & P2, Length
6.90mm; Press-Fit,
LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free

Impact 4 Pair, Right- [783492003](#)
Angle Power Header,
Right Hold-Down,
Module 1: Blade
P1 & P2, Length
6.90mm & 5.70mm;
Press-Fit, LCP,
Glass Filled UL94-
V0, Black, Tray
Packaging, Lead-
Free

Impact 4 Pair, Right- [783492004](#)
Angle Power Header,
Right Hold-Down,
Module 1: Blade P1
& P2 Length 5.70mm
& 6.90mm; Press-
Fit, LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free

Impact 4 Pair, Right- [783492011](#)
Angle Power Header,
2 Modules with Right
Hold-Down, Module
1: Blade P1 & P2,
Length 6.90mm;
Module 2: Blade
P1 & P2, Length
6.90mm; Press-Fit,
LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free

Impact 4 Pair, Right- [783492021](#)
Angle Power Header,
2 Modules with Right
Hold-Down, Module
1: Blade P1 & P2,
Length 5.70mm;
Module 2: Blade
P1 & P2, Length
6.90mm; Press-Fit,
LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free

Impact 4 Pair, Right- [783492022](#)
Angle Power Header,
2 Modules with Right
Hold-Down, Module
1: Blade P1 & P2,
Length 5.70mm;
Module 2: Blade
P1 & P2 Length
5.70mm; Press-Fit,
LCP, Glass Filled
UL94-V0, Black, Tray
Packing

Impact 4 Pair, Right- [783492024](#)
Angle Power Header,
2 Modules with
Right Hold-Down,
Module 1: Blade
P1 & P2, Length
5.70mm & 6.90mm;
Module 2: Blade
P1 & P2 Length
5.70mm; Press-Fit,
LCP, Glass Filled
UL94-V0, Black, Tray
Packing

Impact 4 Pair Right- [783492033](#)
Angle Power Header,
2 Modules with
Left Hold-Down,

Module 1: Blade P1
& P2, Length 6.90
& 5.70mm; Module
2: Blade P1 & P2
Length 6.90mm &
5.70mm, Press-Fit,
LCP, Glass Filled
UL94-V

Impact 4 Pair Right- [783492042](#)
Angle Power Header,
2 Modules with
Left Hold-Down,
Module 1: Blade P1
& P2, Length 5.70
& 6.90mm; Module
2: Blade P1 & P2
Length 5.70mm &
5.70mm, Press-Fit,
LCP, Glass Filled
UL94-V

Impact 4 Pair, Right- [783492044](#)
Angle Power Header,
2 Modules with Right
Hold-Down, Module
1: Blade P1 & P2
Length 6.90mm &
Length 5.70mm;
Module 2: Blade
P1 & P2 Length
6.90mm, Blade
B1 & B2 Length
5.70mm; Press-Fit,
LCP, Glass Filled UL

Impact 4 Pair, [783501001](#)
Right-Angle Power
Receptacle, Left
Hold-Down, Press-
Fit, LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free

Impact 4 Pair, [783501011](#)
Right-Angle Power
Receptacle, 2
Modules with Left
Hold-Down, Press-
Fit, LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free

Impact 4 Pair, [783502001](#)
Right-Angle Power
Receptacle, Right
Hold-Down, Press-
Fit, LCP, Glass Filled
UL94-V0, Black, Tray
Packaging, Lead-
Free

Impact 4 Pair, [783502011](#)
Right-Angle Power
Receptacle, 2
Modules with Right
Hold-Down, Press-
Fit, LCP, Glass Filled
UL94-V0, Black, Tray

This document was generated on 02/27/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[62201-8642](#)