

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0638120800

Status:

Active

Overview:

Application Tooling

Description:

Insertion Tool for Micro-Fit 3.0 and CRC Male and Female Crimp Terminals, 20-30 AWG


Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207121
Comments	See Tooling Specification (PDF) Above
Function	Insertion
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Insertion Hand Tool
UPC	884982223400
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers	
Application Tooling Documents	ATS-638120800-001

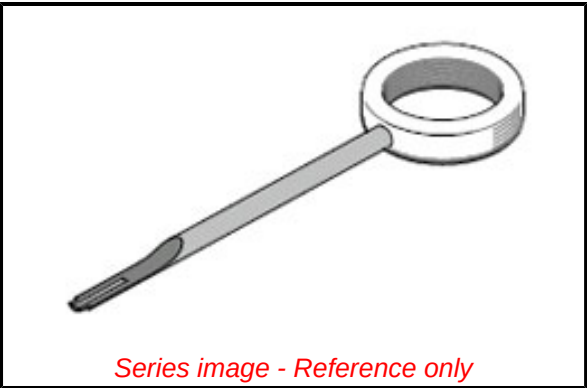

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207121 Series

Use With

43030 , 43031 , 44372 Micro-Fit 3.0 Male and Female Crimp Terminal, 20-30 AWG

Application Tooling Description	FAQ Product #
Micro-Fit+ Crimp Terminal, Female, Tin (Sn) Plating, 26-30 AWG	2064600011
Micro-Fit+ Crimp Terminal, Female, 0.38µm Gold (Au) Plating, 26-30 AWG	2064600012
Micro-Fit+ Crimp Terminal, Female, 0.75µm Gold (Au) Plating, 26-30 AWG	2064600013
Micro-Fit+ Crimp Terminal, Female, Tin (Sn) Plating, 20-24 AWG	2064600021
Micro-Fit+ Crimp Terminal, Female,	2064600022

	0.38µm Gold (Au) Plating, 20-24 AWG Micro-Fit+ Crimp <u>2064600023</u> Terminal, Female, 0.75µm Gold (Au) Plating, 20-24 AWG Micro-Fit+ Crimp <u>2064600031</u> Terminal, Female, Tin (Sn) Plating, 18 AWG Micro-Fit+ Crimp <u>2064600032</u> Terminal, Female, 0.38µm Gold (Au) Plating, 18 AWG Micro-Fit+ Crimp <u>2064600033</u> Terminal, Female, 0.75µm Gold (Au) Plating, 18 AWG Micro-Fit+ Crimp <u>2064600041</u> Terminal, Female, Tin (Sn) Plating, 16 AWG Micro-Fit+ Crimp <u>2064600042</u> Terminal, Female, 0.38µm Gold (Au) Plating, 16 AWG Micro-Fit+ Crimp <u>2064600043</u> Terminal, Female, 0.75µm Gold (Au) Plating, 16 AWG Micro-Fit 3.0 Crimp <u>430300001</u> Terminal, Female, with Tin (Sn) Plated Phosphor Bronze Contact, 20-24 AWG, Reel Micro-Fit 3.0 Crimp <u>430300002</u> Terminal, Female, with Select Gold (Au) Plated Phosphor Bronze Contact, 20-24 AWG, Reel Micro-Fit 3.0 Crimp <u>430300003</u> Terminal, Female, with Select Gold (Au) Plated Phosphor Bronze Contact, 20-24 AWG, Reel Micro-Fit 3.0 Crimp <u>430300004</u> Terminal, Female, with Tin (Sn) Plated Phosphor Bronze Contact, 26-30 AWG, Reel Micro-Fit 3.0 Crimp <u>430300005</u> Terminal, Female, with Select Gold (Au) Plated Phosphor Bronze Contact, 26-30 AWG, Reel Micro-Fit 3.0 Crimp <u>430300006</u> Terminal, Female, with Select Gold (Au) Plated Phosphor
--	---

Bronze Contact,
26-30 AWG, Reel
Micro-Fit 3.0 Crimp [430300007](#)
Terminal, Female,
with Tin (Sn) Plated
Phosphor Bronze
Contact, 20-24 AWG,
Bag
Micro-Fit 3.0 Crimp [430300008](#)
Terminal, Female,
with Select Gold (Au)
Plated Phosphor
Bronze Contact,
20-24 AWG, Bag
Micro-Fit 3.0 Crimp [430300009](#)
Terminal, Female,
with Select Gold (Au)
Plated Phosphor
Bronze Contact,
20-24 AWG, Bag
Micro-Fit 3.0 Crimp [430300010](#)
Terminal, Female,
with Tin (Sn) Plated
Phosphor Bronze
Contact, 26-30 AWG,
Bag
Micro-Fit 3.0 Crimp [430300011](#)
Terminal, Female,
with Select Gold (Au)
Plated Phosphor
Bronze Contact,
26-30 AWG, Bag
Micro-Fit 3.0 Crimp [430300012](#)
Terminal, Female,
with Select Gold (Au)
Plated Phosphor
Bronze Contact,
26-30 AWG, Bag
Micro-Fit 3.0 Crimp [430300038](#)
Terminal, Female,
with Tin (Sn)
Plated Phosphor
Bronze Contact,
18 AWG, .073in /
1.85mm Max
Insulation Outside
Diameter, Reel
Micro-Fit 3.0 [430300039](#)
Crimp Terminal,
Female, with 0.38µm
Select Gold (Au)
Plated Phosphor
Bronze Contact,
18 AWG, .073in /
1.85mm Max
Insulation Outside
Diameter, Reel
Micro-Fit 3.0 [430300040](#)
Crimp Terminal,
Female, with 0.76µm
Select Gold (Au)
Plated Phosphor
Bronze Contact,
18 AWG, .073in /
1.85mm Max

Insulation Outside
Diameter, Reel
Micro-Fit 3.0 Crimp [430310001](#)
Terminal, Male,
with Tin (Sn) Plated
Phosphor Bronze
Contact, 20-24 AWG,
Reel
Micro-Fit 3.0 Crimp [430310002](#)
Terminal, Male,
with 0.38µm Select
Gold (Au) Plated
Phosphor Bronze
Contact, 20-24 AWG,
Reel
Micro-Fit 3.0 Crimp [430310003](#)
Terminal, Male,
with 0.76µm Select
Gold (Au) Plated
Phosphor Bronze
Contact, 20-24 AWG,
Reel
Micro-Fit 3.0 Crimp [430310004](#)
Terminal, Male,
with Tin (Sn) Plated
Phosphor Bronze
Contact, 26-30 AWG,
Reel
Micro-Fit 3.0 Crimp [430310005](#)
Terminal, Male,
with 0.38µm Select
Gold (Au) Plated
Phosphor Bronze
Contact, 26-30 AWG,
Reel
Micro-Fit 3.0 Crimp [430310006](#)
Terminal, Male,
with 0.76µm Select
Gold (Au) Plated
Phosphor Bronze
Contact, 26-30 AWG,
Reel
Micro-Fit 3.0 Crimp [430310007](#)
Terminal, Male,
with Tin (Sn) Plated
Phosphor Bronze
Contact, 20-24 AWG,
Bag
Micro-Fit 3.0 Crimp [430310008](#)
Terminal, Male,
with 0.38µm Select
Gold (Au) Plated
Phosphor Bronze
Contact, 20-24 AWG,
Bag
Micro-Fit 3.0 Crimp [430310009](#)
Terminal, Male,
with 0.76µm Select
Gold (Au) Plated
Phosphor Bronze
Contact, 20-24 AWG,
Bag
Micro-Fit 3.0 Crimp [430310010](#)
Terminal, Male,
with Tin (Sn) Plated

Phosphor Bronze
Contact, 26-30 AWG,
Bag
Micro-Fit 3.0 Crimp [430310011](#)
Terminal, Male,
with 0.38µm Select
Gold (Au) Plated
Phosphor Bronze
Contact, 26-30 AWG,
Bag
Micro-Fit 3.0 Crimp [430310012](#)
Terminal, Male,
with 0.76µm Select
Gold (Au) Plated
Phosphor Bronze
Contact, 26-30 AWG,
Bag
Micro-Fit 3.0 Crimp [430310021](#)
Terminal, Male,
with Tin (Sn)
Plated Phosphor
Bronze Contact,
18 AWG, .073in /
1.85mm Max
Insulation Outside
Diameter, Reel
Micro-Fit 3.0 [430310022](#)
Crimp Terminal,
Male, with 0.38µm
Select Gold (Au)
Plated Phosphor
Bronze Contact,
18 AWG, .073in /
1.85mm Max
Insulation Outside
Diameter, Reel
Micro-Fit 3.0 [430310023](#)
Crimp Terminal,
Male, with 0.76µm
Select Gold (Au)
Plated Phosphor
Bronze Contact,
18 AWG, .073in /
1.85mm Max
Insulation Outside
Diameter, Reel
Micro-Fit TPA Crimp [430315003](#)
Terminal, Male, with
Tin (Sn) Pre-plated
Phosphor Bronze
Contact, 20-24 AWG,
Reel
Micro-Fit TPA Crimp [430315004](#)
Terminal, Male,
with 0.38µm Select
Gold (Au) Plated
Phosphor Bronze
Contact, 20-24 AWG,
Reel
Micro-Fit TPA Crimp [430315005](#)
Terminal, Male,
with 0.76µm Select
Gold (Au) Plated
Phosphor Bronze

Contact, 20-24 AWG,
Reel
Micro-Fit TPA Crimp [430315006](#)
Terminal, Male, with
2.54µm Matte Tin
Plated Phosphor
Bronze Contact,
20-24 AWG, Reel
Micro-Fit TPA Crimp [430315007](#)
Terminal, Male, with
Tin (Sn) Pre-plated
Phosphor Bronze
Contact, 26-30 AWG,
Reel
Micro-Fit TPA Crimp [430315008](#)
Terminal, Male,
with 0.38µm Select
Gold (Au) Plated
Phosphor Bronze
Contact, 26-30 AWG,
Reel
Micro-Fit TPA Crimp [430315009](#)
Terminal, Male,
with 0.76µm Select
Gold (Au) Plated
Phosphor Bronze
Contact, 26-30 AWG,
Reel
Micro-Fit TPA Crimp [430315010](#)
Terminal, Male, with
2.54µm Matte Tin
Plated Phosphor
Bronze Contact,
26-30 AWG, Reel
Micro-Fit 3.0 Crimp [457730001](#)
Terminal, Female,
with Lubricant, with
Tin (Sn) Plated
Phosphor Bronze
Contact, 20-24 AWG,
Reel
Micro-Fit 3.0 Crimp [457730003](#)
Terminal, Female,
with Lubricant, with
Gold (Au) Plated
Phosphor Bronze
Contact, 20-24 AWG,
Reel
Micro-Fit 3.0 Crimp [457730006](#)
Terminal, Female,
with Lubricant, with
Gold (Au) Plated
Phosphor Bronze
Contact, 26-30 AWG,
Reel
Micro-Fit 3.0 Crimp [457730053](#)
Terminal, Female,
with Lubricant, with
Gold (Au) Plated
Phosphor Bronze
Contact, 20-24 AWG,
Reel
CRC Signal Male [561168228](#)
Terminal, Lead-Free,

Chain, Gold (Au)
Plating
CRC Signal Male [561168328](#)
Terminal, Lead-Free,
Loose, Gold (Au)
Plating
CRC Signal Male [561178228](#)
Terminal, Lead-Free,
Chain, Gold (Au)
Plating
CRC Signal Male [561178328](#)
Terminal, Lead-Free,
Loose, Gold (Au)
Plating
CRC Signal Male [561188228](#)
Terminal, Lead-Free,
Chain, Gold (Au)
Plating
CRC Signal Male [561188328](#)
Terminal, Lead-Free,
Loose, Gold (Au)
Plating
CRC Signal Male [561198228](#)
Terminal, Lead-Free,
Chain, Gold (Au)
Plating
CRC Signal Female [561208428](#)
Terminal, Lead-Free,
Gold (Au) Plating,
24-28 AWG, Reel
CRC Signal Female [561208528](#)
Terminal, Lead-Free,
Gold (Au) Plating,
24-28 AWG, Bag
CRC Signal Female [561208628](#)
Terminal, Lead-Free,
Chain, Gold (Au)
Plating
CRC Signal Female [561208728](#)
Terminal, Lead-Free,
Loose, Gold (Au)
Plating
CRC Signal Female [561218428](#)
Terminal, Lead-Free,
Chain, Gold (Au)
Plating
CRC Signal Female [561218528](#)
Terminal, Lead-Free,
Loose, Gold (Au)
Plating
CRC Signal Female [561218628](#)
Terminal, Lead-Free,
Chain, Gold (Au)
Plating
CRC Signal Female [561218728](#)
Terminal, Lead-Free,
Loose, Gold (Au)
Plating

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63812-0800](#)