

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0638244600

Status:


Active

Overview:

Application Tooling

Description:

Extraction Tool for Nano-Fit Power Connectors and Crimp Terminals, 20-26 AWG

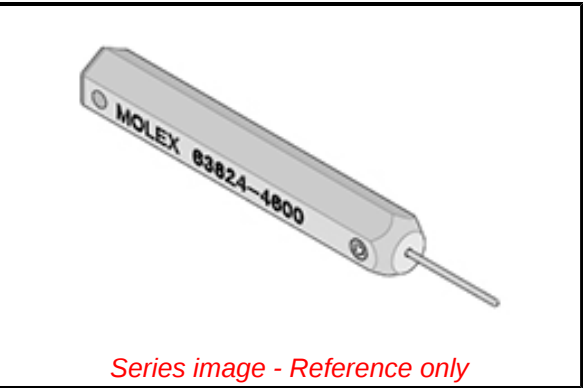

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207121
Comments	See Tooling Specification (PDF) Above
Function	Extraction
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Extraction Hand Tool
UPC	889056010399
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info	
Reference - Drawing Numbers	
Application Tooling Documents	ATS-638244600-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - ED/30/2017 (7 July 2017)	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

207121 Series

Application Tooling Description	FAQ Product #
Nano-Fit Crimp Terminal, Female, 2.54µm Matte Tin (Sn) Plating, 24-26 AWG	1053001100
Nano-Fit Crimp Terminal, Female, 0.38µm Gold (Au) Plating, 24-26 AWG	1053001200
Nano-Fit Crimp Terminal, Female, 0.76µm Gold (Au) Plating, 24-26 AWG	1053001300
Nano-Fit Crimp Terminal, Female, 0.76µm Gold (Au) Plating, Lubricated, 24-26 AWG	1053001400
Nano-Fit Crimp Terminal, Female,	1053002100

2.54µm Matte Tin
(Sn) Plating, 20-22
AWG
Nano-Fit Crimp [1053002200](#)
Terminal, Female,
0.38µm Gold (Au)
Plating, 20-22 AWG
Nano-Fit Crimp [1053002300](#)
Terminal, Female,
0.76µm Gold (Au)
Plating, 20-22 AWG
Nano-Fit Crimp [1053002400](#)
Terminal, Female,
0.76µm Gold (Au)
Plating, Lubricated,
20-22 AWG
Nano-Fit Receptacle [1053071202](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row, 2
Circuits, Black, Glow-
Wire Capable
Nano-Fit Receptacle [1053071203](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row, 3
Circuits, Black, Glow-
Wire Capable
Nano-Fit Receptacle [1053071204](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row, 4
Circuits, Black, Glow-
Wire Capable
Nano-Fit Receptacle [1053071205](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row, 5
Circuits, Black, Glow-
Wire Capable
Nano-Fit Receptacle [1053071206](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row, 6
Circuits, Black, Glow-
Wire Capable
Nano-Fit Receptacle [1053071207](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row, 7
Circuits, Black, Glow-
Wire Capable
Nano-Fit Receptacle [1053071208](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row, 8
Circuits, Black, Glow-
Wire Capable
Nano-Fit Receptacle [1053072202](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row,
2 Circuits, Natural,
Glow-Wire Capable

Nano-Fit Receptacle [1053072203](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row,
3 Circuits, Natural,
Glow-Wire Capable
Nano-Fit Receptacle [1053072204](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row,
4 Circuits, Natural,
Glow-Wire Capable
Nano-Fit Receptacle [1053072205](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row,
5 Circuits, Natural,
Glow-Wire Capable
Nano-Fit Receptacle [1053072206](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row,
6 Circuits, Natural,
Glow-Wire Capable
Nano-Fit Receptacle [1053072207](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row,
7 Circuits, Natural,
Glow-Wire Capable
Nano-Fit Receptacle [1053072208](#)
Housing, TPA
Capable, 2.50mm
Pitch, Single Row,
8 Circuits, Natural,
Glow-Wire Capable
Nano-Fit Receptacle [1053081204](#)
Housing, TPA
Capable, 2.50mm
Pitch, Dual Row, 4
Circuits, Black, Glow-
Wire Capable
Nano-Fit Receptacle [1053081206](#)
Housing, TPA
Capable, 2.50mm
Pitch, Dual Row, 6
Circuits, Black, Glow-
Wire Capable
Nano-Fit Receptacle [1053081208](#)
Housing, TPA
Capable, 2.50mm
Pitch, Dual Row, 8
Circuits, Black, Glow-
Wire Capable
Nano-Fit Receptacle [1053082204](#)
Housing, TPA
Capable, 2.50mm
Pitch, Dual Row,
4 Circuits, Natural,
Glow-Wire Capable
Nano-Fit Receptacle [1053082206](#)
Housing, TPA
Capable, 2.50mm
Pitch, Dual Row,

6 Circuits, Natural,
Glow-Wire Capable
Nano-Fit Receptacle 1053082208
Housing, TPA
Capable, 2.50mm
Pitch, Dual Row,
8 Circuits, Natural,
Glow-Wire Capable

This document was generated on 10/07/2021
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63824-4600](#)