

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0638246210

Status:

Active

Overview:

Application Tooling

Description:

Extraction Tool for Mini-Fit TPA2 Crimp Terminal, 16-24 AWG

Documents:

RoHS Certificate of Compliance (PDF)


General	
Product Family	Application Tooling
Series	207121
Comments	See Tooling Specification (PDF) Above
Function	Extraction
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	Mini-Fit TPA2
Tool Type	Extraction Hand Tool
UPC	889056632065
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers

Application Tooling Documents

ATS-638246210-001

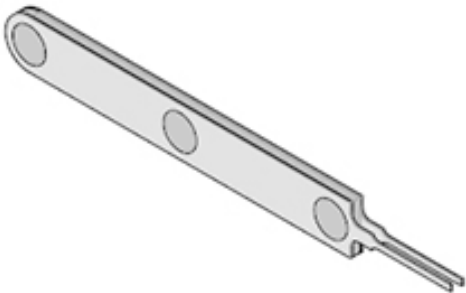

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207121 Series

Application Tooling Description	FAQ Product #
Mini-Fit TPA2/ Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 16 AWG, 1.98-2.55mm Insulation Diameter, Reel	1727181111
Mini-Fit TPA2/ Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 16 AWG, 1.98-2.55mm Insulation Diameter, Bag	1727181112
Mini-Fit TPA2/ Sigma Female Crimp Terminal, Brass, Pre-Plated Tin (Sn), 16 AWG, 1.98-2.55mm	1727181121

	Insulation Diameter, Reel Mini-Fit TPA2/ <u>1727181122</u> Sigma Female Crimp Terminal, Brass, Pre- Plated Tin (Sn), 16 AWG, 1.98-2.55mm Insulation Diameter, Bag Mini-Fit TPA2/ <u>1727182111</u> Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 16 AWG, 2.55-3.14mm Insulation Diameter, Reel Mini-Fit TPA2/ <u>1727182112</u> Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 16 AWG, 2.55-3.14mm Insulation Diameter, Bag Mini-Fit TPA2/ <u>1727182121</u> Sigma Female Crimp Terminal, Brass, Pre- Plated Tin (Sn), 16 AWG, 2.55-3.14mm Insulation Diameter, Reel Mini-Fit TPA2/ <u>1727182122</u> Sigma Female Crimp Terminal, Brass, Pre- Plated Tin (Sn), 16 AWG, 2.55-3.14mm Insulation Diameter, Bag Mini-Fit TPA2/ <u>1727183111</u> Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 18-20 AWG, 1.42-2.10mm Insulation Diameter, Reel Mini-Fit TPA2/ <u>1727183112</u> Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 18-20 AWG, 1.42-2.10mm Insulation Diameter, Bag Mini-Fit TPA2/ <u>1727183121</u> Sigma Female Crimp Terminal, Brass, Pre-Plated Tin (Sn), 18-20 AWG, 1.42-2.10mm Insulation Diameter, Reel Mini-Fit TPA2/ <u>1727183122</u> Sigma Female
--	---

	Crimp Terminal, Brass, Pre-Plated Tin (Sn), 18-20 AWG, 1.42-2.10mm Insulation Diameter, Bag Mini-Fit TPA2/ <u>1727184111</u> Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 18-20, 22+22 AWG, 2.10-2.85mm Insulation Diameter, Reel, Double Crimp Option Mini-Fit TPA2/ <u>1727184112</u> Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 18-20 AWG, 2.10-2.85mm Insulation Diameter, Bag Mini-Fit TPA2/ <u>1727184121</u> Sigma Female Crimp Terminal, Brass, Pre-Plated Tin (Sn), 18-20, 22+22 AWG, 2.10-2.85mm Insulation Diameter, Reel, Double Crimp Option Mini-Fit TPA2/ <u>1727184122</u> Sigma Female Crimp Terminal, Brass, Pre-Plated Tin (Sn), 18-20 AWG, 2.10-2.85mm Insulation Diameter, Bag Mini-Fit TPA2/ <u>1727185111</u> Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 22-24 AWG, 1.07-1.65mm Insulation Diameter, Reel Mini-Fit TPA2/ <u>1727185112</u> Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 22-24 AWG, 1.07-1.65mm Insulation Diameter, Bag Mini-Fit TPA2/ <u>1727185121</u> Sigma Female Crimp Terminal, Brass, Pre-Plated Tin (Sn), 22-24 AWG, 1.07-1.65mm Insulation Diameter, Reel
--	---

	Mini-Fit TPA2/ Sigma Female Crimp Terminal, Brass, Pre-Plated Tin (Sn), 22-24 AWG, 1.07-1.65mm Insulation Diameter, Bag	<u>1727185122</u>
	Mini-Fit TPA2/ Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 22-24 AWG, 1.65-2.38mm Insulation Diameter, Reel	<u>1727186111</u>
	Mini-Fit TPA2/ Sigma Female Crimp Terminal, Phosphor Bronze, Pre-Plated Tin (Sn), 22-24 AWG, 1.65-2.38mm Insulation Diameter, Bag	<u>1727186112</u>
	Mini-Fit TPA2/ Sigma Female Crimp Terminal, Brass, Pre-Plated Tin (Sn), 22-24 AWG, 1.65-2.38mm Insulation Diameter, Reel	<u>1727186121</u>
	Mini-Fit TPA2/ Sigma Female Crimp Terminal, Brass, Pre-Plated Tin (Sn), 22-24 AWG, 1.65-2.38mm Insulation Diameter, Bag	<u>1727186122</u>
	Mini-Fit TPA2/ Sigma Male Crimp Terminal, Brass, Pre- Plated Tin (Sn), 16 AWG, 1.98-2.55mm Insulation Diameter, Reel	<u>1727651121</u>
	Mini-Fit TPA2/ Sigma Male Crimp Terminal, Brass, Pre- Plated Tin (Sn), 16 AWG, 1.98-2.55mm Insulation Diameter, Bag	<u>1727651122</u>
	Mini-Fit TPA2/ Sigma Male Crimp Terminal, Brass, Pre- Plated Tin (Sn), 16 AWG, 2.55-3.14mm Insulation Diameter, Reel	<u>1727652121</u>
	Mini-Fit TPA2/ Sigma Male Crimp Terminal, Brass, Pre- Plated Tin (Sn), 16	<u>1727652122</u>

	AWG, 2.55-3.14mm Insulation Diameter, Bag Mini-Fit TPA2/ <u>1727653121</u> Sigma Male Crimp Terminal, Brass, Pre-Plated Tin (Sn), 18-20 AWG, 1.42-2.10mm Insulation Diameter, Reel Mini-Fit TPA2/ <u>1727653122</u> Sigma Male Crimp Terminal, Brass, Pre-Plated Tin (Sn), 18-20 AWG, 1.42-2.10mm Insulation Diameter, Bag Mini-Fit TPA2/ <u>1727654121</u> Sigma Male Crimp Terminal, Brass, Pre-Plated Tin (Sn), 18-20, 22+22 AWG, 2.10-2.85mm Insulation Diameter, Reel, Double Crimp Option Mini-Fit TPA2/ <u>1727654122</u> Sigma Male Crimp Terminal, Brass, Pre-Plated Tin (Sn), 18-20 AWG, 2.10-2.85mm Insulation Diameter, Bag Mini-Fit TPA2/ <u>1727655121</u> Sigma Male Crimp Terminal, Brass, Pre-Plated Tin (Sn), 22-24 AWG, 1.07-1.65mm Insulation Diameter, Reel Mini-Fit TPA2/ <u>1727655122</u> Sigma Male Crimp Terminal, Brass, Pre-Plated Tin (Sn), 22-24 AWG, 1.07-1.65mm Insulation Diameter, Bag Mini-Fit TPA2/ <u>1727656121</u> Sigma Male Crimp Terminal, Brass, Pre-Plated Tin (Sn), 22-24 AWG, 1.65-2.38mm Insulation Diameter, Reel Mini-Fit TPA2/ <u>1727656122</u> Sigma Male Crimp Terminal, Brass, Pre-Plated Tin (Sn), 22-24 AWG,
--	--

1.65-2.38mm
Insulation Diameter,
Bag

This document was generated on 10/06/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63824-6210](#)