

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0638850800

Status:

Active

Overview:

Application Tooling

Description:

Mini-Mac Applicator

Documents:

RoHS Certificate of Compliance (PDF)


General	
Product Family	Application Tooling
Series	207127
Comments	The Molex Tape Applicator requires an industry standard crimp press with a 4way air like the Molex TM-3000: 638017200 , 638017300 , and the Molex TM-4000: 638017600
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	Mini-Mac
Tool Type	Applicator
UPC	822348758555
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers

Application Tooling Documents

ATS-638850800-001, TM-638800000-001, TM-638800000SP-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

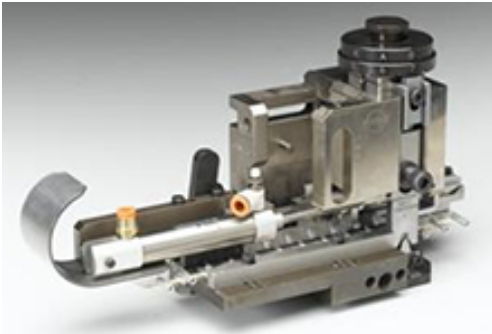

Series image - Reference only

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207127 Series

Use With

Molex TM-3000: [638017200](#) , [638017300](#) , Molex TM-4000: [638017600](#) , and Most Industry Standard Presses or Wire Process Machines

Application Tooling Description	FAQ Product #
InsulKrimp Quick Disconnect, Female, for 18-22 (0.80-0.35mm ²) Wire, Mylar Tape, Tab 5.21 x 0.51mm	190170003
InsulKrimp Quick Disconnect, Female, for 18-22 (0.80-0.35mm ²) Wire, Mylar Tape, Tab 2.79 x 0.51mm	190170004
InsulKrimp Quick Disconnect, Female, for 18-22 (0.80-0.35mm ²) Wire,	190170006

Mylar Tape, Tab 2.79
x 0.81mm
InsulKrimp Quick 190170009
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Mylar Tape, Tab 4.75
x 0.81mm
InsulKrimp Quick 190170012
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Mylar Tape, Tab 4.75
x 0.51mm
InsulKrimp Quick 190170017
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Mylar Tape, Tab 6.35
x 0.81mm
Avikrimp Quick 190190003
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Mylar Tape, Tab 2.79
x 0.51mm
Avikrimp Quick 190190005
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Mylar Tape, Tab 2.79
x 0.81mm
Avikrimp Quick 190190009
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Mylar Tape, Tab 4.75
x 0.81mm
Avikrimp Quick 190190011
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Mylar Tape, Tab 4.75
x 0.51mm
Avikrimp Quick 190190013
Disconnect,
Female, for 18-22
(0.80-0.35mm²) Wire,
Mylar Tape, Tab 6.35
x 0.81mm
Quixon Quick 192740003
Disconnect,
InsulKrimp Style,
Female, Partially
Insulated Red, 18-22
AWG, Mylar Tap
Quixon Quick 192750003
Disconnect, Avikrimp
Style, Female,
Partially Insulated
Red, 18-22 AWG,
Mylar Tap

This document was generated on 07/30/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63885-0800](#)