

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0638851300

Status:

Active

Overview:

Application Tooling

Description:

FineAdjust Pneumatic Applicator for Ring and Spade Terminals, 18-22 AWG

Documents:

RoHS Certificate of Compliance (PDF)


General	
Product Family	Application Tooling
Series	207127
Comments	The Molex Tape Applicator requires an industry standard crimp press with a 4way air like the Molex TM-3000: 638017200 , 638017300 , and the Molex TM-4000: 638017600
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	Mini-Mac
Tool Type	Applicator
UPC	822348758616
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers

Application Tooling Documents

ATS-638851300-001, TM-638800000-001, TM-638800000SP-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

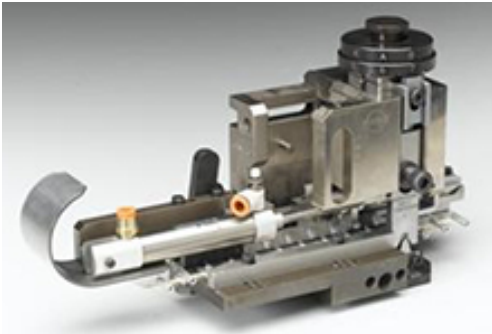

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Relevant	
REACH SVHC	
Not Relevant	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Relevant

Search Parts in this Series

207127 Series

Use With

Molex TM-3000: [638017200](#) , [638017300](#) , Molex TM-4000: [638017600](#) , and Most Industry Standard Presses or Wire Process Machines

Application Tooling Description	FAQ Product #
InsulKrimp Ring Tongue Terminal for 18-22 AWG Wire	190700006
InsulKrimp Ring Tongue Terminal for 18-22 AWG Wire	190700008
InsulKrimp Ring Tongue Terminal for 18-22 AWG Wire	190700010
InsulKrimp Ring Tongue Terminal for 18-22 AWG Wire	190700012
InsulKrimp Ring Tongue Terminal for 18-22 AWG Wire	190700014

InsulKrimp Ring	<u>190700017</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700022</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700024</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700027</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700035</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700039</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700042</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700045</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700052</u>
Tongue Terminal for	
18-22 AWG Wire	
Avikrimp Ring	<u>190730008</u>
Tongue Terminal for	
18 to 22 AWG Wire,	
Stud Size 4 (M2.6),	
Length 18.00mm,	
Mylar Tape Carrier	
Avikrimp Ring	<u>190730012</u>
Tongue Terminal for	
18 to 22 AWG Wire,	
Stud Size 6 (M3.5),	
Length 22.00mm,	
Mylar Tape Carrier	
Avikrimp Ring	<u>190730015</u>
Tongue Terminal for	
18 to 22 AWG Wire,	
Stud Size 8 (M4),	
Length 22.00mm,	
Mylar Tape Carrier	
Avikrimp Ring	<u>190730019</u>
Tongue Terminal for	
18 to 22 AWG Wire,	
Stud Size 10 (M5),	
Length 22.00mm,	
Mylar Tape Carrier	
Avikrimp Ring	<u>190730026</u>
Tongue Terminal for	
18 to 22 AWG Wire,	
Stud Size 1/4" (M6),	
Length 26.90mm,	
Mylar Tape Carrier	
Avikrimp Ring	<u>190730028</u>
Tongue Terminal for	
18 to 22 AWG Wire,	
Stud Size 5/16" (M8),	
Length 26.90mm,	
Mylar Tape Carrier	
Avikrimp Ring	<u>190730033</u>
Tongue Terminal for	

	18 to 22 AWG Wire, Stud Size 3/8" (M9), Length 32.00mm, Mylar Tape Carrier Avikrimp Ring 190730037
	Tongue Terminal for 18 to 22 AWG Wire, Stud Size 4 (M2.6), Length 20.60mm, Mylar Tape Carrier Avikrimp Ring 190730040
	Tongue Terminal for 18 to 22 AWG Wire, Stud Size 5 (M3), Length 20.60mm, Mylar Tape Carrier Avikrimp Ring 190730043
	Tongue Terminal for 18 to 22 AWG Wire, Stud Size 8 (M4), Length 20.60mm, Mylar Tape Carrier Avikrimp Ring 190730050
	Tongue Terminal for 18 to 22 AWG Wire, Stud Size 10 (M5), Length 20.70mm, Mylar Tape Carrier InsulKrimp Snap 190990008
	Spade for 18-22 AWG Wire, Stud Size 5 (M3), Mylar Tape Carrier, Red InsulKrimp Snap 190990010
	Spade Terminal for 18-22 AWG Wire, Stud Size 5 (M3)-6, Mylar Tape Carrier, Red InsulKrimp Snap 190990014
	Spade for 18-22 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier, Red InsulKrimp Snap 190990016
	Spade for 18-22 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier, Red InsulKrimp Flanged 191210006
	Spade Tongue Terminal for 18-22 AWG Wire, Stud Size 6 (M3.5), Length 19.84mm, Mylar Tape Carrier InsulKrimp Flanged 191210008
	Spade Tongue Terminal for 18-22 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier InsulKrimp Flanged 191210010
	Spade Tongue Terminal for 18-22

AWG Wire, Stud
Size 10 (M5), Mylar
Tape Carrier
Avikrimp Flanged [191270009](#)
Spade Tongue
Terminal for 22-18
AWG Wire, Stud
Size 6 (M3.5), Mylar
Tape Carrier
Avikrimp Flanged [191270011](#)
Spade Tongue
Terminal for 22-18
AWG Wire, Stud
Size 8 (M4), Mylar
Tape Carrier
Avikrimp Flanged [191270013](#)
Spade Tongue
Terminal for 22-18
AWG Wire, Stud
Size 10 (M5), Mylar
Tape Carrier
InsulKrimp Block [191310030](#)
Spade Tongue
Terminal for 18
to 22 AWG Wire,
Stud Size 6 (M3.5),
Length 19.91mm,
Mylar Tape Carrier
Avikrimp Block [191390019](#)
Spade Terminal for
18-22 AWG Wire,
Stud Size 6 (M3.5),
Width 6.22mm, Mylar
Tape Carrier
InsulKrimp Spade [191440002](#)
Tongue Terminal for
18-22 AWG Wire,
Tape and Reel
SPADE [191440004](#)
INSULKRIMP
TAPED
(AA-235-08XT)
Avikrimp Spade [191980005](#)
Tongue Terminal for
22-18 AWG Wire,
Stud Size 8 (M4)
Avikrimp Spade [191980007](#)
Tongue Terminal for
22-18 AWG Wire,
Stud Size 10 (M5)
Avikrimp Spade [191980071](#)
Tongue Terminal for
22-18 AWG Wire,
Stud Size 6 (M3.5)
Avikrimp Wire Pin [192130010](#)
Terminal for 22-18
AWG Wire, Mylar
Tape Carrier

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63885-1300](#)