

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0638851400

Status:

Active

Overview:

Application Tooling

Description:

Mini-Mac Applicator

Documents:

RoHS Certificate of Compliance (PDF)


General	
Product Family	Application Tooling
Series	207127
Comments	The Molex Tape Applicator requires an industry standard crimp press with a 4way air like the Molex TM-3000: 638017200 , 638017300 , and the Molex TM-4000: 638017600
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	Mini-Mac
Tool Type	Applicator
UPC	822350835473
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers

Application Tooling Documents

ATS-638851400-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

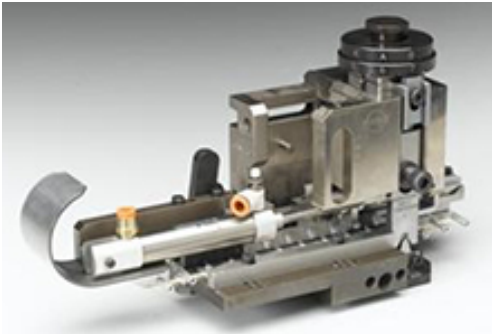

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Not Reviewed

ELV

Not Reviewed

RoHS Phthalates

Not Reviewed

Search Parts in this Series

207127 Series

Use With

Molex TM-3000: [638017200](#) , [638017300](#) , Molex TM-4000: [638017600](#) , and Most Industry Standard Presses or Wire Process Machines

Application Tooling Description	FAQ Product #
InsulKrimp Star Ring Tongue Terminal for 18-22 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier	190750002
InsulKrimp Star Ring Tongue Terminal for 18-22 AWG Wire, Stud Size 8 (M4), Mylar Tape Carrier	190750004
InsulKrimp Steel Star Ring Tongue Terminal for 18-22 AWG Wire, Stud Size 6 (M3.5), Mylar Tape Carrier	190750008

InsulKrimp Steel	<u>190750010</u>
Star Ring Tongue	
Terminal for 18-22	
AWG Wire, Stud	
Size 8 (M4), Mylar	
Tape Carrier	
InsulKrimp Steel	<u>190750012</u>
Star Ring Tongue	
Terminal for 18-22	
AWG Wire, Stud	
Size 10 (M5), Mylar	
Tape Carrier	
Avikrimp Star Ring	<u>190770002</u>
Tongue Terminal for	
18-22 AWG Wire,	
Stud Size 6 (M3.5),	
Mylar Tape Carrier	
Avikrimp Star Ring	<u>190770006</u>
Tongue Terminal for	
18-22 AWG Wire,	
Stud Size 8 (M4),	
Mylar Tape Carrier	
Avikrimp Star Ring	<u>190770008</u>
Tongue Terminal for	
18-22 AWG Wire,	
Stud Size 10 (M5),	
Mylar Tape Carrier	
Avikrimp Steel	<u>190770010</u>
Star Ring Tongue	
Terminal 18-22 AWG	
Wire, Stud Size 6	
(M3.5), Mylar Tape	
Carrier	
Avikrimp Steel	<u>190770012</u>
Star Ring Tongue	
Terminal 18-22 AWG	
Wire, Stud Size 8	
(M4), Mylar Tape	
Carrier	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63885-1400](#)