

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0638858100

Status:

Active

Overview:

Application Tooling

Description:

Mini-Mac Applicator

Documents:

RoHS Certificate of Compliance (PDF)


General	
Product Family	Application Tooling
Series	207127
Comments	The Molex Tape Applicator requires an industry standard crimp press with a 4way air like the Molex TM-3000: 638017200 , 638017300 , and the Molex TM-4000: 638017600
Function	Crimp
Geographic Area	Global
Level of Automation	Automatic, Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	Mini-Mac
Tool Type	Applicator
UPC	822350358835
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Reference - Drawing Numbers

Application Tooling Documents

638858100-001, TM-638800000-001, TM-638800000SP-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

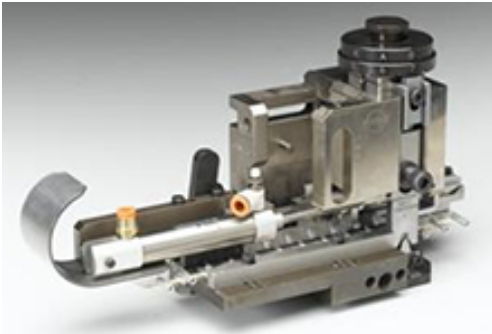

Series image - Reference only

EU ELV	
Not Reviewed	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207127 Series

Use With

Molex TM-3000: [638017200](#) , [638017300](#) , Molex TM-4000: [638017600](#) , and Most Industry Standard Presses or Wire Process Machines

Application Tooling Description	FAQ Product #
InsulKrimp Quick Disconnect, Female, for 18-22 (0.80-0.35mm²), Box, Tab 6.35 x 0.81mm	190030008
Krimptite Quick Disconnect, Male, for 14-16 (2.00-1.30mm²) Wire, Mylar Tape, Tab 6.35 x 0.81mm	190220026
Krimptite Butt Splice for 14-16 AWG Wire	191890010
Krimptite Temp-Term Ring Tongue Terminal for 14 to	192030045

16 AWG Wire, Stud
Size 1/4" (M6), Mylar
Tape Carrier
Krimptite Temp- 192030048
Term Ring Tongue
Terminal for 14 to
16 AWG Wire, Stud
Size 6 (M3.5), Mylar
Tape Carrier
Krimptite Temp- 192030050
Term Ring Tongue
Terminal for 14 to
16 AWG Wire, Stud
Size 8 (M4), Mylar
Tape Carrier
Krimptite Temp- 192030052
Term Ring Tongue
Terminal for 14 to
16 AWG Wire, Stud
Size 10 (M5), Mylar
Tape Carrier
VersaKrimp Butt 192150115
Splice for 14-16
AWG Wire, Tape and
Reel

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[63885-8100](#)