

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0640010300

Status:

Active

Overview:

Application Tooling

Description:

PremiumGrade Hand Crimp Tool for Insulkrimp Terminals and Splices, 10-22 AWG (Rings, Spades, Hooks, Block Spades and Flanged Spades)

Documents:

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Comments

Function

Geographic Area

Level of Automation

More Detailed Tech Information

Overview

Product Name

Tool Type

UPC

Warranty Disclaimer

Application Tooling

207129

Type RHT

Crimp

Global

Manual

applicationtooling@molex.com

Application Tooling

N/A

Hand Crimp Tool

756054563649

CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info


Engineering Number

RHT-1993

Reference - Drawing Numbers

Application Tooling Documents

TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

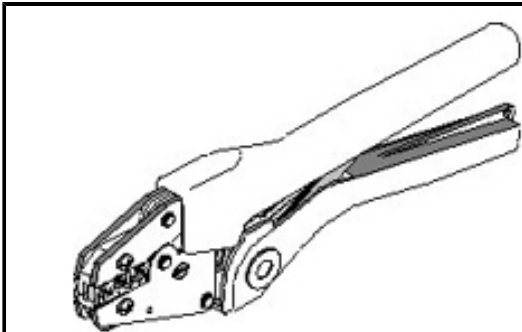

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Not Reviewed

REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

207129 Series

Use With

Loose Piece Terminals

Application Tooling Description	FAQ Product #
InsulKrimp Snap Plug, for 18-22 AWG Wire, 24.13mm Length	190340002
InsulKrimp Snap Plug, for 18-22 AWG Wire, 22.61mm Length	190340005
InsulKrimp Snap Plug, for 14-16 AWG Wire, 24.13mm Length	190340007
InsulKrimp Ring Tongue Terminal for 18-22 AWG Wire	190700005

InsulKrimp Ring	<u>190700007</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700009</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700011</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700013</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700015</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700021</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700023</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700026</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700033</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700038</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700040</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700044</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700051</u>
Tongue Terminal for	
18-22 AWG Wire	
InsulKrimp Ring	<u>190700059</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700063</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700065</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700067</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700069</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700071</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700073</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700075</u>
Tongue Terminal for	
14-16 AWG Wire	

InsulKrimp Ring	<u>190700078</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700083</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700086</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700090</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700099</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700102</u>
Tongue Terminal for	
14-16 AWG Wire	
InsulKrimp Ring	<u>190700109</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Ring	<u>190700115</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Ring	<u>190700119</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Ring	<u>190700121</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Ring	<u>190700123</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Ring	<u>190700130</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Ring	<u>190700132</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Ring	<u>190700136</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Ring	<u>190700143</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Ring	<u>190700145</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Ring	<u>190700150</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Ring	<u>190700153</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Ring	<u>190700155</u>
Tongue Terminal for	
10-12 AWG Wire	
InsulKrimp Snap	<u>190990007</u>
Spade Terminal for	
18-22 AWG Wire,	
Red	
InsulKrimp Snap	<u>190990009</u>
Spade Terminal for	
18-22 AWG Wire,	
Red	

	InsulKrimp Snap Spade Terminal for 18-22 AWG Wire, Red	<u>190990013</u>
	InsulKrimp Snap Spade Terminal for 18-22 AWG Wire, Red	<u>190990015</u>
	InsulKrimp Snap Spade Terminal for 14-16 AWG Wire, Blue	<u>190990025</u>
	InsulKrimp Snap Spade Terminal for 14-16 AWG Wire, Blue	<u>190990027</u>
	InsulKrimp Snap Spade Terminal for 14-16 AWG Wire, Blue	<u>190990032</u>
	InsulKrimp Snap Spade Terminal for 14-16 AWG Wire, Blue	<u>190990034</u>
	InsulKrimp Snap Spade Terminal for 10-12 AWG Wire, Yellow	<u>190990044</u>
	InsulKrimp Snap Spade Terminal for 10-12 AWG Wire, Yellow	<u>190990048</u>
	InsulKrimp Snap Spade Terminal for 10-12 AWG Wire, Yellow	<u>190990050</u>
	InsulKrimp Flanged Spade Tongue Terminal for 18-22 AWG Wire, Stud Size 6 (M3.5), Length 19.84mm	<u>191210005</u>
	InsulKrimp Flanged Spade Tongue Terminal for 18-22 AWG Wire, Stud Size 8 (M4)	<u>191210007</u>
	InsulKrimp Flanged Spade Tongue Terminal for 18-22 AWG Wire, Stud Size 10 (M5)	<u>191210009</u>
	InsulKrimp Flanged Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 6 (M3.5)	<u>191210026</u>
	InsulKrimp Flanged Spade Tongue Terminal for 14-16 AWG Wire, Stud Size 8 (M4)	<u>191210028</u>
	InsulKrimp Flanged Spade Tongue Terminal for 14-16	<u>191210030</u>

AWG Wire, Stud
Size 10 (M5), Length
20.19mm
InsulKrimp Flanged [191210046](#)
Spade Tongue
Terminal for 10-12
AWG Wire, Stud
Size 6 (M3.5), Width
8.13mm
InsulKrimp Flanged [191210047](#)
Spade Tongue
Terminal for 10-12
AWG Wire, Stud
Size 8 (M4), Width
8.13mm
InsulKrimp Flanged [191210049](#)
Spade Tongue
Terminal for 10-12
AWG Wire, Stud
Size 10 (M5), Width
8.13mm
InsulKrimp Flanged [191210051](#)
Spade Tongue
Terminal for 10-12
AWG Wire, Stud
Size 6 (M3.5), Width
9.53mm
InsulKrimp Flanged [191210053](#)
Spade Tongue
Terminal for 10-12
AWG Wire, Stud
Size 8 (M4), Width
9.53mm
InsulKrimp Block [191310002](#)
Spade Tongue
Terminal for 10 to
12 AWG Wire, Stud
Size 10 (M5), Length
27.31mm
InsulKrimp Block [191310004](#)
Spade Tongue
Terminal for 10 to
12 AWG Wire, Stud
Size 8 (M4), Length
27.31mm
InsulKrimp Block [191310006](#)
Spade Tongue
Terminal for 10
to 12 AWG Wire,
Stud Size 6 (M3.5),
Length 27.31mm
InsulKrimp Block [191310014](#)
Spade Tongue
Terminal for 14 to
16 AWG Wire, Stud
Size 10 (M5), Length
19.80mm
InsulKrimp Block [191310018](#)
Spade Tongue
Terminal for 14 to
16 AWG Wire, Stud
Size 8 (M4), Length
19.80mm
InsulKrimp Block [191310020](#)
Spade Tongue

	Terminal for 14 to 16 AWG Wire, Stud Size 6 (M3.5), Length 19.80mm InsulKrimp Block Spade Tongue	<u>191310023</u>
	Terminal for 14 to 16 AWG Wire, Stud Size 6 (M3.5), Length 19.94mm InsulKrimp Block Spade Tongue	<u>191310025</u>
	Terminal for 14 to 16 AWG Wire, Stud Size 4 (M2.6), Length 19.94mm InsulKrimp Block Spade Tongue	<u>191310031</u>
	Terminal for 18 to 22 AWG Wire, Stud Size 6 (M3.5), Length 19.91mm InsulKrimp Block Spade Tongue	<u>191310034</u>
	Terminal for 18 to 22 AWG Wire, Stud Size 10 (M5), Length 19.94mm InsulKrimp Block Spade Tongue	<u>191310036</u>
	Terminal for 18 to 22 AWG Wire, Stud Size 8 (M4), Length 19.94mm InsulKrimp Block Spade Tongue	<u>191310038</u>
	Terminal for 18 to 22 AWG Wire, Stud Size 6 (M3.5), Length 19.94mm InsulKrimp Block Spade Tongue	<u>191310042</u>
	Terminal for 18 to 22 AWG Wire, Stud Size 6 (M3.5), Length 6.35mm InsulKrimp Block Spade Tongue	<u>191310045</u>
	Terminal for 18 to 22 AWG Wire, Stud Size 4 (M2.6), Length 18.47mm InsulKrimp Block Spade Tongue	<u>191310047</u>
	Terminal for 18 to 22 AWG Wire, Stud Size 2 (M2), Length 18.47mm InsulKrimp Spade Tongue Terminal for	<u>191440001</u>
	18-22 AWG Wire InsulKrimp Spade Tongue Terminal for 18-22 AWG Wire	<u>191440003</u>

InsulKrimp Spade Tongue Terminal for 18-22 AWG Wire	<u>191440005</u>
InsulKrimp Spade Tongue Terminal for 14-16 AWG Wire	<u>191440015</u>
InsulKrimp Spade Tongue Terminal for 14-16 AWG Wire	<u>191440018</u>
InsulKrimp Spade Tongue Terminal for 14-16 AWG Wire	<u>191440020</u>
InsulKrimp Spade Tongue Terminal for 14-16 AWG Wire	<u>191440024</u>
InsulKrimp Spade Tongue Terminal for 14-16 AWG Wire	<u>191440026</u>
InsulKrimp Spade Tongue Terminal for 10-12 AWG Wire	<u>191440037</u>
InsulKrimp Spade Tongue Terminal for 10-12 AWG Wire	<u>191440039</u>
InsulKrimp Spade Tongue Terminal for 10-12 AWG Wire	<u>191440042</u>
InsulKrimp Butt Splice for 18-22 AWG Wire	<u>191540004</u>
InsulKrimp Butt Splice for 18-22 AWG Wire	<u>191540011</u>
InsulKrimp Butt Splice for 14-16 AWG Wire	<u>191540015</u>
InsulKrimp Butt Splice for 14-16 AWG Wire	<u>191540023</u>
InsulKrimp Butt Splice for 10-12 AWG Wire	<u>191540028</u>
InsulKrimp Butt Splice for 10-12 AWG Wire	<u>191540037</u>
Perma-Seal Male Snap Plug for 18-22 AWG Wire, Diameter 3.96mm	<u>191640010</u>
Perma-Seal Male Snap Plug for 14-16 AWG Wire, Diameter 3.96mm	<u>191640040</u>
Butt - Funnel Entry Splice for 14-16 AWG Wire	<u>192020019</u>
Funnel Entry Butt Splice for 14-16 AWG Wire	<u>192020027</u>
NylaKrimp Butt Splice for 14-16 AWG Wire	<u>192020031</u>
NylaKrimp Butt Splice for 10-12 AWG Wire	<u>192020049</u>

Funnel Entry Butt Splice for 18-22 AWG Wire	<u>192020063</u>
InsulKrimp 4 Way Splice for 18-22 AWG Wire	<u>192040003</u>
InsulKrimp 3 Way Splice for 18-22 AWG Wire	<u>192040004</u>
InsulKrimp 3 Way Splice for 14-16 AWG Wire	<u>192040014</u>
InsulKrimp 4 Way Splice for 10-12 AWG Wire	<u>192040025</u>
InsulKrimp 3 Way Splice for 10-12 AWG Wire	<u>192040026</u>
NylaKrimp Parallel Splice for 18-22 AWG Wire	<u>192070002</u>
NylaKrimp Parallel Splice for 14-16 AWG Wire	<u>192070004</u>
NylaKrimp Parallel Splice for 10-12 AWG Wire	<u>192070005</u>
InsulKrimp Wire Pin Terminal for 12-10 AWG Wire	<u>192120001</u>
InsulKrimp Wire Pin Terminal for 22-18 AWG Wire	<u>192120003</u>
InsulKrimp Wire Pin Terminal for 16-14 AWG Wire	<u>192120005</u>

This document was generated on 10/07/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64001-0300](#)