

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0640010800

Status:

Active

Overview:

Application Tooling

Description:

PremiumGrade Hand Crimp Tool for Avikrimp Female Full Insulated Quick Disconnect Terminals, for 18-22 AWG with Insulation Diameter no greater than 3.175mm MAX


Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207129
Comments	Type RHT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	756054591895
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info	
Engineering Number	RHT-5760

Reference - Drawing Numbers	
Application Tooling Documents	ATS-640010800-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

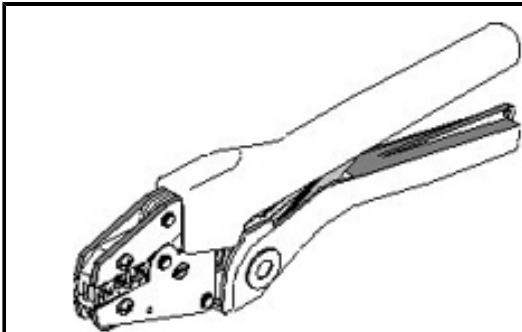

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)9139-DC (19 Jan 2021)	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

207129 Series

Use With

Loose Piece Terminals

Application Tooling Description	FAQ Product #
Avikrimp Fully Insulated Quick Disconnect, Female for 18-22 AWG Wire, Box	190020001
Avikrimp Fully Insulated Quick Disconnect, Female, for 18-22 AWG Wire, Box	190020005
Avikrimp Fully Insulated Quick Disconnect, Female, for 18-22 AWG Wire, Box	190020009
Avikrimp Fully Insulated Quick	190020013

Disconnect, Female,
for 18-22 AWG Wire,
Box
Avikrimp Fully 190020016
Insulated Quick
Disconnect, Female,
for 18-22 AWG Wire,
Box
Avikrimp Fully 190020019
Insulated Quick
Disconnect, Female,
for 18-22 AWG Wire,
Box
Avikrimp Fully 190020021
Insulated Quick
Disconnect, Female,
for 18-22 AWG Wire,
Box
Quixon Quick 192770002
Disconnect, Avikrimp
Style, Female, Fully
Insulated Red, 18-22
AWG, Loose

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64001-0800](#)