

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0640011900

Status:

Active

Overview:

Application Tooling

Description:

Hand Crimp Tool

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207129
Comments	Type RHT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	Avikrimp, InsulKrimp
Tool Type	Hand Crimp Tool
UPC	822348373314
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info


Engineering Number

RHT-5766

Reference - Drawing Numbers

Application Tooling Documents

640011900-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

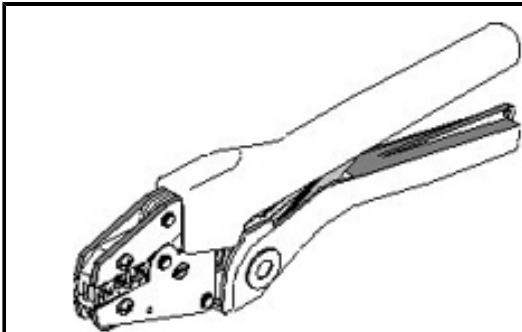

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Contained Per - ED/30/2017 (7 July 2017)	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

207129 Series

Use With

Loose Piece Terminals

Application Tooling Description	FAQ Product #
InsulKrimp Star Ring Tongue Terminal for 14-16 AWG Wire, Stud Size 6 (M3.5)	190750013
InsulKrimp Star Ring Tongue Terminal for 14-16 AWG Wire, Stud Size 8 (M4)	190750015
InsulKrimp Star Ring Tongue Terminal for 14-16 AWG Wire, Stud Size 10 (M5)	190750017
InsulKrimp Steel Star Ring Tongue Terminal for 14-16 AWG Wire, Stud Size 6 (M3.5)	190750019

	InsulKrimp Steel	<u>190750021</u>
	Star Ring Tongue	
	Terminal for 14-16	
	AWG Wire, Stud	
	Size 8 (M4)	
	InsulKrimp Steel	<u>190750023</u>
	Star Ring Tongue	
	Terminal for 14-16	
	AWG Wire, Stud	
	Size 10 (M5)	
	Avikrimp Star Ring	<u>190770015</u>
	Tongue Terminal	
	14-16 AWG Wire,	
	Stud Size 6 (M3.5)	
	Avikrimp Star Ring	<u>190770017</u>
	Tongue Terminal	
	14-16 AWG Wire,	
	Stud Size 8 (M4)	
	Avikrimp Star Ring	<u>190770019</u>
	Tongue Terminal	
	14-16 AWG Wire,	
	Stud Size 10 (M5)	
	Avikrimp Steel	<u>190770021</u>
	Star Ring Tongue	
	Terminal 14-16 AWG	
	Wire, Stud Size 6	
	(M3.5)	
	Avikrimp Steel	<u>190770023</u>
	Star Ring Tongue	
	Terminal 14-16 AWG	
	Wire, Stud Size 8	
	(M4)	
	Avikrimp Steel	<u>190770025</u>
	Star Ring Tongue	
	Terminal 14-16 AWG	
	Wire, Stud Size 10	
	(M5)	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64001-1900](#)