

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0640034200

Status:

Active

Overview:

Application Tooling

Description:

PremiumGrade Hand Crimp Tool for Flag Krimptite/Vibrakrimp Un-insulated Female Quick Disconnect Terminals, 14-22 AWG

Documents:

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Comments

Function

Geographic Area

Level of Automation

More Detailed Tech Information

Overview

Product Name

Tool Type

UPC

Warranty Disclaimer

Application Tooling

207129

Type RHT

Crimp

Global

Manual

applicationtooling@molex.com

Application Tooling

N/A

Hand Crimp Tool

822348074396

CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info


Engineering Number

RHT-NIFG

Reference - Drawing Numbers

Application Tooling Documents

ATS-640034200-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

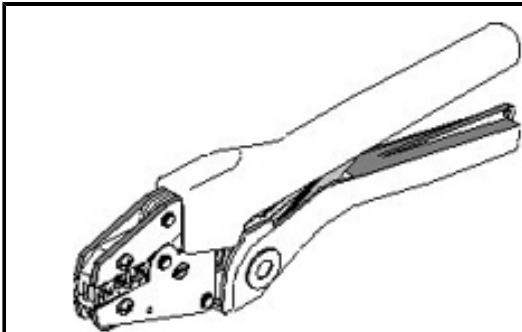

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Relevant

Search Parts in this Series

207129 Series

Use With

Loose Piece Terminals

Application Tooling Description	FAQ Product #
Flag Krimptite Quick Disconnect, Female, for 18-22 (0.80-0.35mm²) Wire, Box, Tab 4.75 x 0.51mm	190080001
Flag Krimptite Quick Disconnect, Female, for 18-22 (0.80-0.35mm²) Wire, Box, Tab 4.75 x 0.81mm	190080002
Flag Krimptite Quick Disconnect, Female, for 18-22 (0.80-0.35mm²) Wire, Box, Tab 6.35 x 0.81mm	190080006

Flag Krimptite Quick Disconnect, Female, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 4.75 x 0.51mm	<u>190080019</u>
Flag Krimptite Quick Disconnect, Female, for 14-16 (2.00-1.30mm ²) Wire, Box, Tab 6.35 x 0.81mm	<u>190080024</u>
VibraKrimp Quick Disconnect Flag, Female, for 18-22 AWG Wire	<u>190090001</u>
VibraKrimp Quick Disconnect Flag, Female, for 18-22 AWG Wire	<u>190090003</u>
VibraKrimp Quick Disconnect Flag, Female, for 14-16 AWG Wire	<u>190090010</u>
VibraKrimp Quick Disconnect Flag, Female, for 14-16 AWG Wire	<u>190090012</u>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64003-4200](#)