

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0643183011

Status:


Active

Overview:

CMC and CMX Sealed, Hybrid, Modular Connectors

Description:

.635mm, 1.50mm, 2.80mm, Power CMC Connector, 28 Circuits, Right Wire Output, Black Coding, Mat Sealed

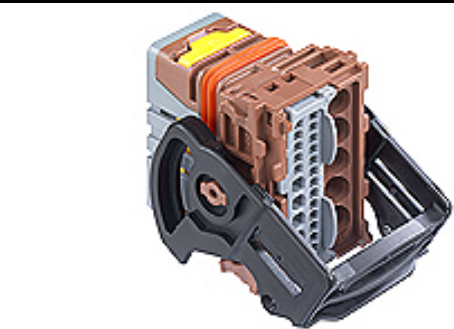

Series image - Reference only

Documents:	
3D Model	Application Specification AS-64318-002-SP-001 (PDF)
Drawing (PDF)	Application Specification AS-98420-001-001 (PDF)
3D Model (PDF)	Application Specification AS-98420-001-CH-001 (PDF)
Product Specification PS-64321-001-001 (PDF)	Application Specification AS-98420-001-FR-001 (PDF)
Application Specification AS-64318-002-001 (PDF)	Application Specification AS-98420-001-SP-001 (PDF)
Application Specification AS-64318-002-CH-001 (PDF)	Datasheet (PDF)
Application Specification AS-64318-002-FR-001 (PDF)	RoHS Certificate of Compliance (PDF)

Application tooling part link	
Application Tooling Part Link	63812-1100
Application Tooling Part Link	63824-1200
General	
Product Family	Crimp Housings
Series	64318
Application	Automotive, Power, Wire-to-Board
Comments	* Current tested on a fully loaded connector, current for temperature increase of 40°C. Current max = 21.0A for 2.80mm Terminal (5.00mm² wire), 12.0A for 1.50mm Terminal (2.00mm² wire), 2.5A for 0.635mm Terminal(0.75mm² wire) *
More Detailed Tech Information	Sealed, high-density, power, modular connecting system for Power Train and Body Electronics applications in cars, trucks, busses
Overview	CMC and CMX Sealed, Hybrid, Modular Connectors
Product Name	CMC
UPC	883906135133
Physical	
Circuits (maximum)	28
Circuits Detail	5x 2.8mm, 5 x 1.5mm, 18 x 0.635mm terminals
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	35.290/g
Number of Rows	3
Packaging Type	Carton
Panel Mount	No
Pitch - Mating Interface	2.54mm, 3.50mm, 6.75mm
Polarized to Mating Part	Yes
Stackable	No

EU ELV
Compliant

EU RoHS
Compliant
REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free
Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
64318 Series

Mates With
CMC Header [47745](#) - please contact Molex for details

Use With
CMC CP Female Terminal [64322](#) (0.635mm), [64323](#) (1.50mm), [64324](#) (2.80mm) . CMC Wire Cap [643201301](#) . Sealing Plugs [643251010](#) , [643251023](#) , [643251091](#)

Application Tooling | [FAQ](#)
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Continuity Test Pen Assembly	638121100

Temperature Range - Operating	-40° to +125°C	Unlocking Tool for CMC and CMX Receptacle Connector	638241200
Electrical			
Current - Maximum per Contact	12.0A, 2.5A, 21.0A		
Solder Process Data			
Lead-freeProcess Capability	N/A		
Material Info			
Reference - Drawing Numbers			
Application Specification	AS-64318-002-001, AS-64318-002-CH-001, AS-64318-002-FR-001, AS-64318-002-SP-001, AS-98420-001-001, AS-98420-001-CH-001, AS-98420-001-FR-001, AS-98420-001-SP-001		
Product Specification	PS-64321-001-001		
Sales Drawing	SD-64318-001-001		

This document was generated on 12/27/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[64318-3011](#)